



OFDC B8G Fiber Optic Splice/Patch Closure, X-press version, Gel Cable sealing, 1 pre-installed 18-fiber splice tray, 4 pre-installed 12 fiber trays, no adapters, no splitter

- Advanced gel sealing technology ensures fast and easy field handling without a need for special tools
- Individual access to drop cable connection area and separate zones for looped cable storage for most cable types
- Compact and modular design suited for wraparound drop cable installation, enabling faster deployments
- Allows easy pass-through cabling and integration of optical components, even at later deployment stages

Product Classification

Regional Availability	Australia/New Zealand
Product Type	Single-ended, rectangular fiber closure
Product Series	OFDC


General Specifications

Cable Capacity, Branch	2 Round 4.0–11.0 mm (0.15–0.43 in)
Cable Capacity, Drop	16 Round 0–5.5 mm (0–0.21 in)
Cable Sealing Type	Compressed gel
Color	Black
Mounting	Manhole Pedestal Strand Wall
Port Type	Non-hardened SC/APC adapter
Splice Tray Included, quantity	1
Splice Tray Type Included	12-fiber, single element
Splicing Capacity, maximum	96
Splicing Type, Supported	Single fusion

Dimensions

Height	128 mm 5.039 in
Width	156 mm 6.142 in
Length	324 mm 12.756 in
Splice Protector Length, maximum	45 mm 1.772 in

Ordering Tree

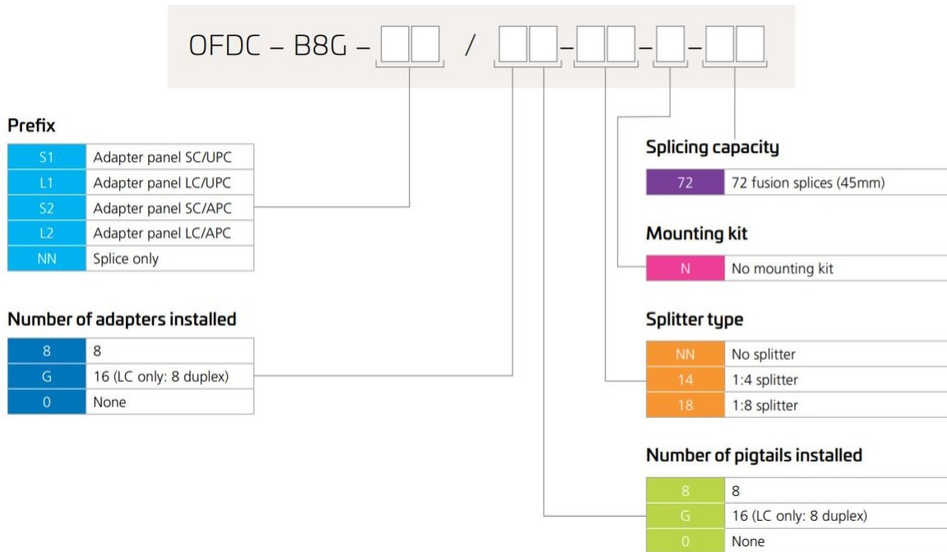

Material Specifications

Material Type Rugged polymer

Optical Specifications

Fiber Type G.657.A1

Environmental Specifications

Installation temperature -5 °C to +45 °C (+23 °F to +113 °F)

Storage Temperature -30 °C to +60 °C (-22 °F to +140 °F)

Relative Humidity 93%, non-condensing

Environmental Space Above ground | Below ground

Qualification Standards IEC 60529, IP68 + 2 m waterhead

UV Resistance UV stabilized

Packaging and Weights

Packaging quantity 1

Packaging Type Box | Carton

Regulatory Compliance/Certifications

Agency

CHINA-ROHS
ISO 9001:2015
REACH-SVHC
ROHS

Classification

Below maximum concentration value
Designed, manufactured and/or distributed under this quality management system
Compliant as per SVHC revision on www.commscope.com/ProductCompliance
Compliant

