



OFDC B8G Fiber Optic Splice/Patch Closure, X-press version, Gel Cable sealing, 1 pre-installed 18-fiber splice tray, 4 pre-installed 12 fiber trays, 8 SC/APC adapters, 1-8 splitter pre-conn at drop side, mounting bracket

- Advanced gel sealing technology ensures fast and easy field handling without a need for special tools
- Individual access to drop cable connection area and separate zones for looped cable storage for most cable types
- Compact and modular design suited for wraparound drop cable installation, enabling faster deployments
- Allows easy pass-through cabling and integration of optical components, even at later deployment stages

Product Classification

Regional Availability	Australia/New Zealand
Product Type	Single-ended, rectangular fiber closure
Product Series	OFDC

General Specifications


Cable Sealing Type	Compressed gel
Color	Black
Mounting	Manhole Pedestal Strand Wall

Dimensions

Height	128 mm 5.039 in
Width	156 mm 6.142 in
Length	324 mm 12.756 in

Ordering Tree

760241297 | OFDC-B8G-SX2/8-NN-18-BRKT-KIT

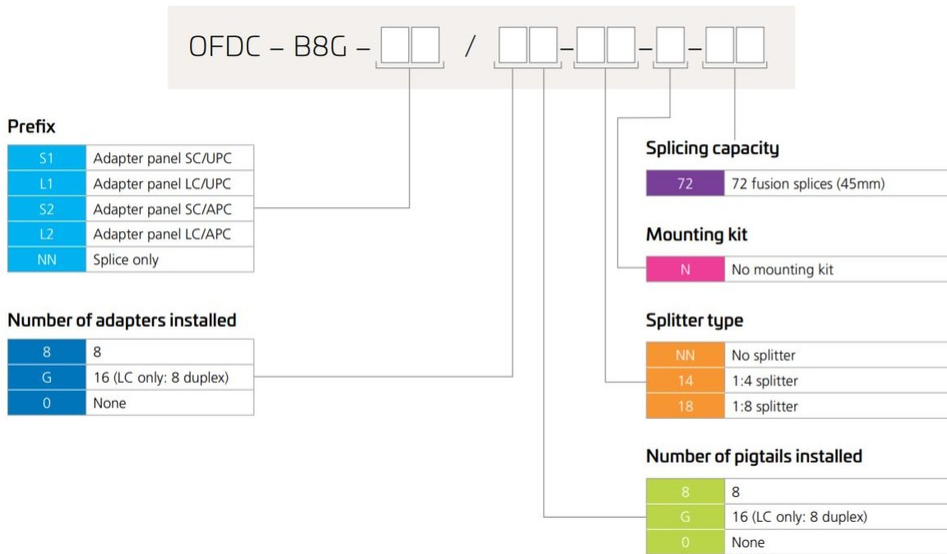

Material Specifications

Material Type Rugged polymer

Environmental Specifications

Installation temperature -5 °C to +45 °C (+23 °F to +113 °F)
Storage Temperature -30 °C to +60 °C (-22 °F to +140 °F)
Relative Humidity 93%, non-condensing
Environmental Space Above ground | Below ground
Qualification Standards IEC 60529, IP68 + 2 m waterhead
UV Resistance UV stabilized

Packaging and Weights

Packaging quantity 1
Packaging Type Box | Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

760241297 | OFDC-B8G-SX2/8-NN-18-BRKT-KIT

ROHS

Compliant

