


FPP-12SU-60M

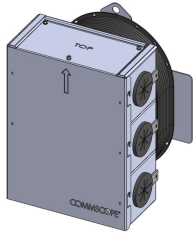

HELIAX® Fiber Plug and Play 6 RRU Solution that will interface with Ericsson, Nokia, Huawei or ZTE RRU's, 60M

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Outdoor junction box
Product Brand	HELIAX®

General Specifications


Application	For use with Ericsson, Nokia, Huawei or ZTE remote radio units (RRU's)
Cable Entry Location	Side
Cable Entry, quantity, maximum, right	3
Cable Entry, quantity, maximum, top	3
Color	Gray
Mounting	Pipe, 76.2–101.6 mm (3.0–4.0 in) OD Wall

Dimensions

Height	406.4 mm 16 in
Width	406.4 mm 16 in
Depth	234.95 mm 9.25 in

Outline Drawing

FPP-12SU-60M

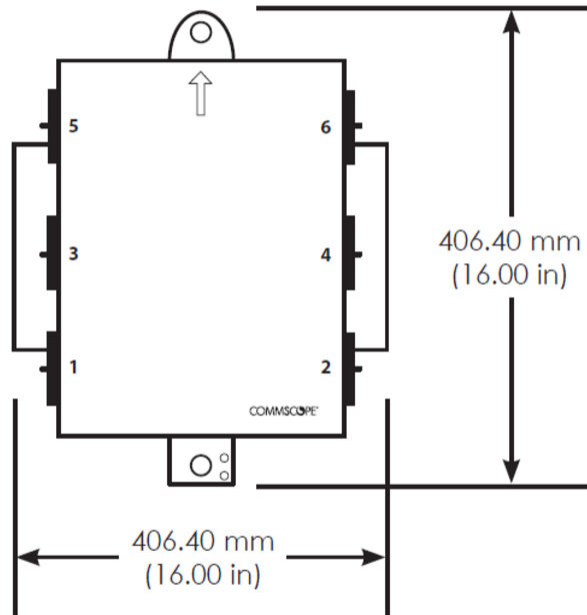

Material Specifications

Material Type Aluminum

Environmental Specifications

Environmental Space Indoor | Outdoor

Qualification Standards IEC 60529:2001, IP67

Packaging and Weights

Included Mounting kit

Weight, net 11.299 kg | 24.91 lb

Regulatory Compliance/Certifications

FPP-12SU-60M

Agency

CHINA-ROHS
ISO 9001:2015
REACH-SVHC
ROHS
UK-ROHS

Classification

Below maximum concentration value
Designed, manufactured and/or distributed under this quality management system
Compliant as per SVHC revision on www.commscope.com/ProductCompliance
Compliant
Compliant

