


6-557315-2 | MP-88U-R-5

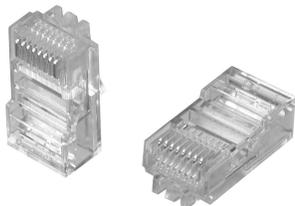

Modular Plug Kit, 8P/8C, unshielded, round, 5.1 mm max cable jack OD, 8-position, 500/bag

Product Classification

Regional Availability

Asia | Australia/New Zealand | EMEA | Latin America | North America

Portfolio

CommScope®

Product Type

Modular plug

General Specifications

ANSI/TIA Category

5

Cable Type

Round, unshielded

Conductor Type

Solid | Stranded

Interface

RJ45

Positions/Loaded Contacts

8/8

Termination Type

IDC

Dimensions

Compatible Cable Diameter, maximum

5.1 mm | 0.201 in

Compatible Insulated Conductor Diameter, maximum

0.99 mm | 0.039 in

Compatible Insulated Conductor Diameter, minimum

0.86 mm | 0.034 in

Contact Plating Thickness

1.27 µm

Compatible Conductor Gauge, solid

26–24 AWG

Compatible Conductor Gauge, stranded

26–24 AWG

Electrical Specifications

Current Rating, maximum

0.75 A

Insulation Resistance, minimum

500 mOhm

Safety Voltage Rating

150 Vac

6-557315-2 | MP-88U-R-5

Material Specifications

Contact Base Material	Phosphor Bronze
Contact Plating Material	Gold
Material Type	Glass filled polycarbonate

Mechanical Specifications

Plug Insertion Life, minimum	750 times
-------------------------------------	-----------

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Relative Humidity	Up to 93%, non-condensing
Safety Standard	UL 1863

Packaging and Weights

Packaging quantity	500
Packaging Type	Bag Box Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

