

# LLC-850-5



## Low Loss Combiner Kit 850, 5 MHz BW

- dc Transparent 2G path
- Daisy-chainable alarm output
- Real-time clock
- Built-in web interface
- Built-in SNMP agent
- Field upgradable firmware

**OBSOLETE**

This product was discontinued on: December 1, 2019

### Product Classification

**Product Type**     Combiner

### General Specifications

**Application**     Indoor

### Electrical Specifications

**License Band**     Cellular

### Included Products

- |             |   |  |
|-------------|---|--|
| C61B01P36   | – | Power Cable Assembly for Receive Multicouplers and Low Loss Combiners, 8 |
| C61B01P3601 |   | m  |
| C61B01P51   | – | Alarm Cable Assembly for Low Loss Combiners, 8 m                         |

# C61B01P36 | C61B01P3601

---



Power Cable Assembly for Receive Multicouplers and Low Loss Combiners, 8 m

## Product Classification

**Product Type** Power cable assembly

## General Specifications


**Application** Low loss combiner | Receive multicoupler  
**Conductor Type** 24 AWG  
**Conductors, quantity** 3  
**Connector Interface** Pluggable terminal block

## Dimensions

**Length** 8000 mm | 314.961 in

# C61B01P36 | C61B01P3601

## Outline Drawing

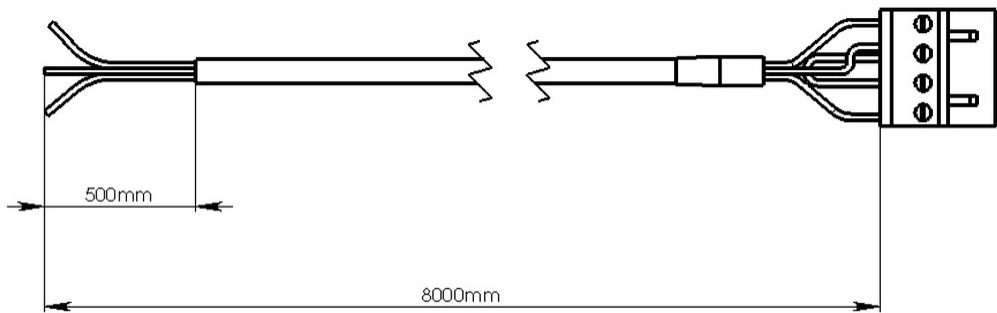

## Material Specifications


**Material Type**                      PVC

## Packaging and Weights

**Weight, net**                      0.2 kg | 0.441 lb

# C61B01P51

---

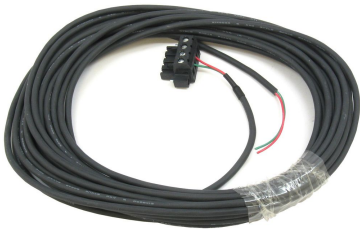

Alarm Cable Assembly for Low Loss Combiners, 8 m

## Product Classification

**Product Type** Alarm cable assembly

## General Specifications

**Application** Low loss combiner

**Conductor Type** 24 AWG

**Conductors, quantity** 2


**Connector Interface** Pluggable terminal block

## Dimensions

**Length** 8000 mm | 314.961 in

# C61B01P51

## Outline Drawing

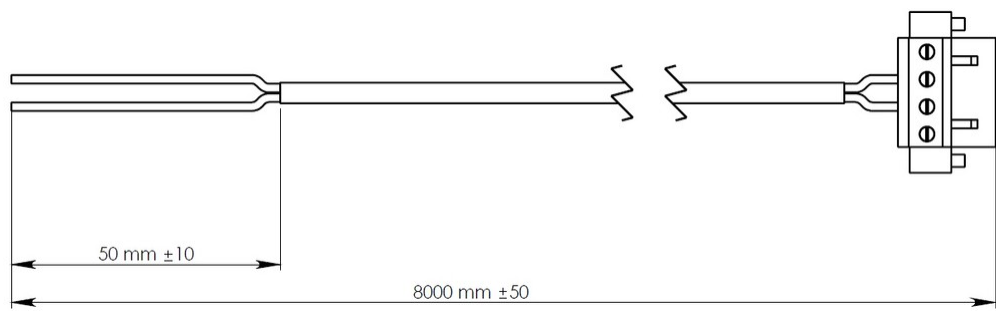

## Material Specifications

**Material Type**                      PVC

## Packaging and Weights

**Weight, net**                      120 g | 0.265 lb