

T-200-UW-43-F-16

Low PIM Termination 200 W Load, 0-6000MHz



OBSOLETE

This product was discontinued on: September 30, 2021

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Product Type	Termination Load

General Specifications

Device Type	Termination Load
Application	Indoor/Outdoor
Color	Silver
Inner Contact Plating	Silver
Interface	4.3-10 Female
Outer Contact Plating	Trimetal

Dimensions

Height	126 mm 4.961 in
Width	130 mm 5.118 in
Length	232 mm 9.134 in

Electrical Specifications

3rd Order IMD	-165 dBc
3rd Order IMD Test Method	Two +43 dBm carriers
Average Power, maximum	200 W
Impedance	50 ohm

T-200-UW-43-F-16

Operating Frequency Band


0 – 6000 MHz

VSWR at Frequency Band

1.2:1 @ 0–555 MHz | 1.2:1 @ 555–2700 MHz | 1.3:1 @ 2700–6000 MHz

T-200-UW-43-F-16

Derating Curve

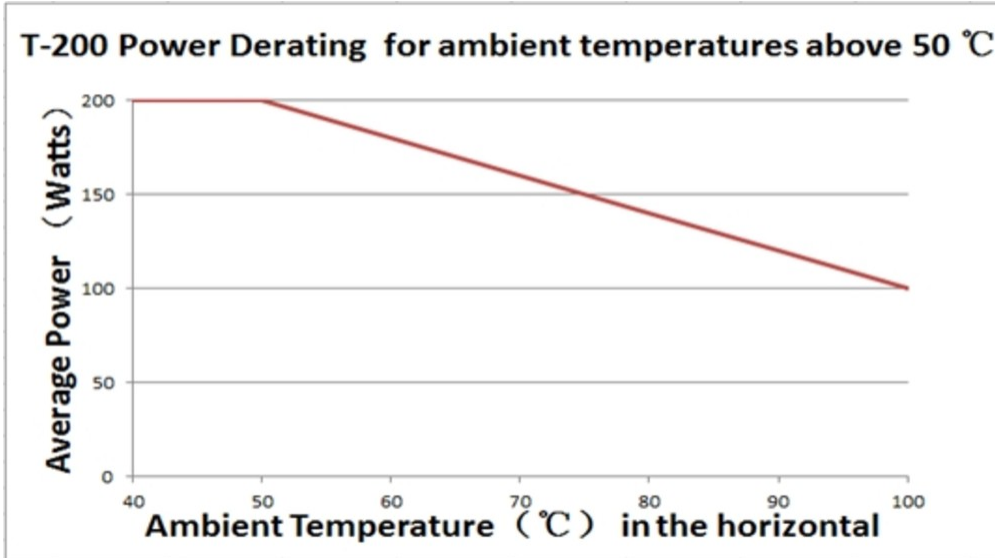

Environmental Specifications

Operating Temperature	-25 °C to +50 °C (-13 °F to +122 °F)
Relative Humidity	Up to 100%
Ingress Protection Test Method	IEC 60529:2001, IP65

Packaging and Weights

Height, packed	200 mm 7.874 in
Width, packed	200 mm 7.874 in
Length, packed	400 mm 15.748 in
Weight, gross	5 kg 11.023 lb
Weight, net	4.55 kg 10.031 lb