


# FPCA-77YZ

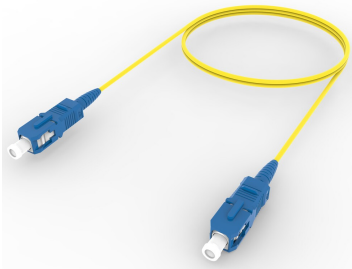

Fiber Optic Patch Cord, singlemode, 1.2 mm LSZH jacket, SC/UPC-SC /UPC, yellow

- 1.2 mm diameter cable provides a 65% space savings over commonly used 2.0 mm cable
- 1.2 mm diameter fiber patch cords use Reduced Bend Radius (RBR) fiber cable
- Typically used in environments where space constraints and cable routing prove most challenging

## Product Classification

Regional Availability	Europe   Middle East/Africa
Product Type	Fiber patch cord, simplex
Product Series	FPCA

## General Specifications


Connector A, quantity	1
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	1
Color, boot B	Blue
Color, connector B	Blue
Interface, Connector A	SC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Yellow
Total Fibers, quantity	1

## Dimensions

Diameter Over Jacket	1.2 mm   0.047 in
----------------------	-------------------

## Ordering Tree

# FPCA-77YZ

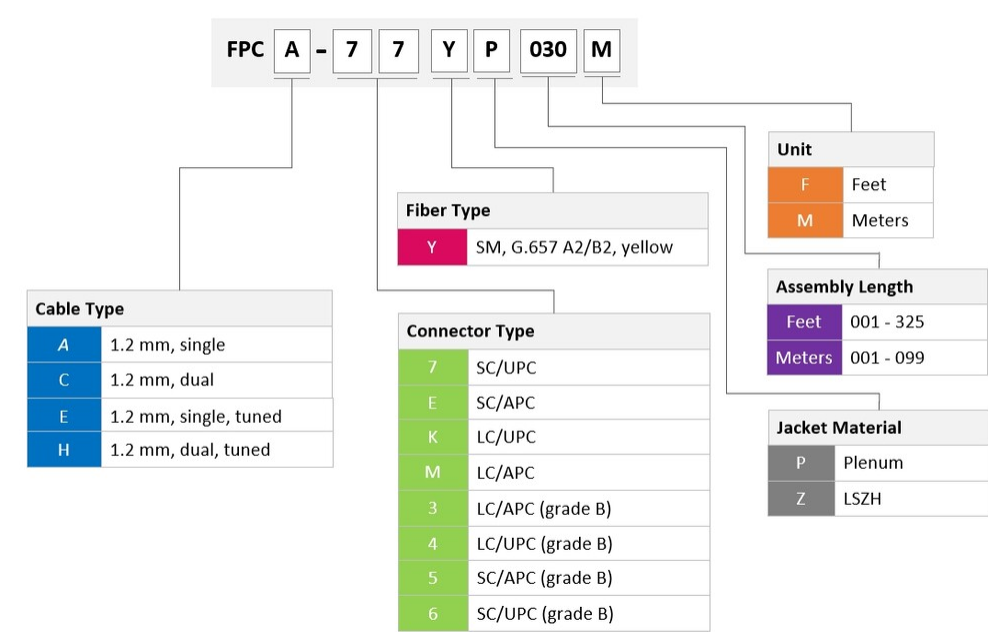

## Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2/B2
Insertion Loss, maximum, connector A	55 dB
Insertion Loss, maximum, connector B	55 dB
Insertion Loss, ULL, maximum, connector A	0.25 dB
Insertion Loss, ULL, maximum, connector B	0.25 dB

## Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
---------------------	-------------------------------

## Packaging and Weights

Packaging quantity	1
--------------------	---

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted

# FPCA-77YZ

---

UK-ROHS

Compliant/Exempted



## Included Products

760243025 – 1.2 mm LSZH Simplex Cable  
POC-FO-CAB-SX-8G-1.2MM-YL