


# FGSB-MDSP-F

---

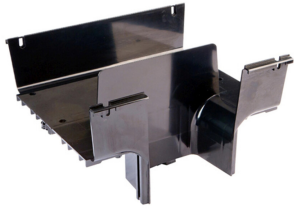

FiberGuide® Downspout with 6in Exit, 4x12in, Black

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Downspout
<b>Product Brand</b>	FiberGuide®
<b>Product Series</b>	FGS

## General Specifications

<b>Color</b>	Black
<b>Orientation</b>	Horizontal
<b>Section Type</b>	Downspout

## Dimensions

<b>Height</b>	211.125 mm   8.312 in
<b>Width</b>	347.218 mm   13.67 in
<b>Length</b>	381 mm   15 in
<b>System Dimensions</b>	102 mm x 305 mm (4 in x 12 in)

## Ordering Tree

# FGSB-MDSP-F



## Section Color

9	empty	yellow
	B	black

## Section Size

10	2B	4 x 6 in, 4 x 4 in dual drop
	A	4 x 4 in
	A/I	4 x 4 in, insertable
	B	4 x 6 in, 4 x 4 in drop
	B/I	4 x 6 in, insertable
	C	2 x 2 in, extended
	EX-	extended
	F	4 x 12 in, 4 x 6 in drop
	F/I	4 x 12 in, 4 x 6 in drop, insertable
	G	2 x 6 in, 2 x 2 in drop
	IMP	4 x 6 in, dual drop with divider
	M	4 x 18 in

## Material Specifications

**Material Type** Engineering Thermoplastic

## Environmental Specifications

**Flammability Rating** CSA S143 | UL 2024 | UL 94 V-0

**Halogen Characteristics** Blue Angel | TCO '99 | WEEE

**Safety Standard** CSA | UL

## Packaging and Weights

**Weight, net** 2.172 kg | 4.788 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



