


# FGSB-MH9E-A

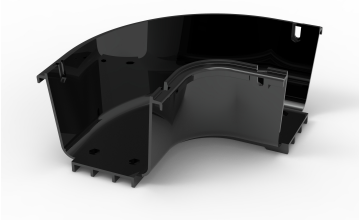

FiberGuide® 90° Horizontal Elbow, 4x4in, Black

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Elbow
<b>Product Brand</b>	FiberGuide®
<b>Product Series</b>	FGS

## General Specifications

<b>Angle/Bend Direction</b>	90°
<b>Color</b>	Black
<b>Orientation</b>	Horizontal
<b>Section Type</b>	Elbow section

## Dimensions

<b>System Dimensions</b>	102 mm x 102 mm (4 in x 4 in)
--------------------------	-------------------------------

## Ordering Tree



### Section Color

9	empty	yellow
	B	black

\* Support brackets only come in black

### Section Size

1 0	A	4 x 4 in
	B	4 x 6 in
	F	4 x 12 in
	F-VS	4 x 12 in , variable support bracket
	G	2 x 6 in
	M	4 x 18 in

# FGSB-MH9E-A

---

## Material Specifications

**Material Type** Engineering Thermoplastic

## Environmental Specifications

**Flammability Rating** CSA S143 | UL 2024 | UL 94 V-0

**Halogen Characteristics** Blue Angel | TCO '99 | WEEE

**Safety Standard** CSA | UL

## Packaging and Weights

**Weight, net** 0.405 kg | 0.893 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

