


SVF59TG

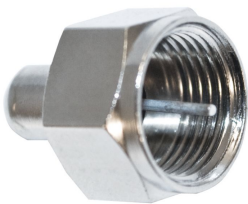

HomeConnect® F Type Port Non-locking Terminator, brass

OBSOLETE

Product Classification

Product Type	Terminator
Product Brand	HomeConnect®

General Specifications

Device Type	Non-locking terminator
Parking Port	Not included

Dimensions

Contact Pin Diameter	0.762 mm 0.03 in
----------------------	--------------------

Electrical Specifications

Return Loss, minimum	30 dB
Average Power	0.25 W
Impedance	75 ohm
Operating Frequency Band	5 – 1800 MHz
Shielding Effectiveness, minimum	100 dB

Material Specifications

Material Type	Brass
Plating	Nickel

Environmental Specifications

SVF59TG

Operating Temperature	-40 °C to +60 °C (-40 °F to +140 °F)
Safety Standard	CE EN 60728-4 SCTE

Packaging and Weights

Height, packed	190.5 mm 7.5 in
Width, packed	241.3 mm 9.5 in
Length, packed	330.2 mm 13 in
Carton Quantity	5000
Weight, gross	19.051 kg 42 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

