


CL-1220-U

Universal Cable Ladder Kit, 38 in x 20 ft, 12-hole rung

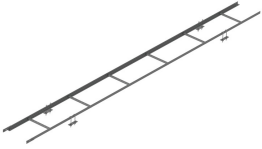

Product Classification

Product Type Ladder kit

General Specifications

Cable Runs, quantity 12

Mounting Round and angle legs

Dimensions


Height 76.2 mm | 3 in

Width 96.5.2 mm | 38 in

Length 6096 mm | 240 in

CL-1220-U

Outline Drawing

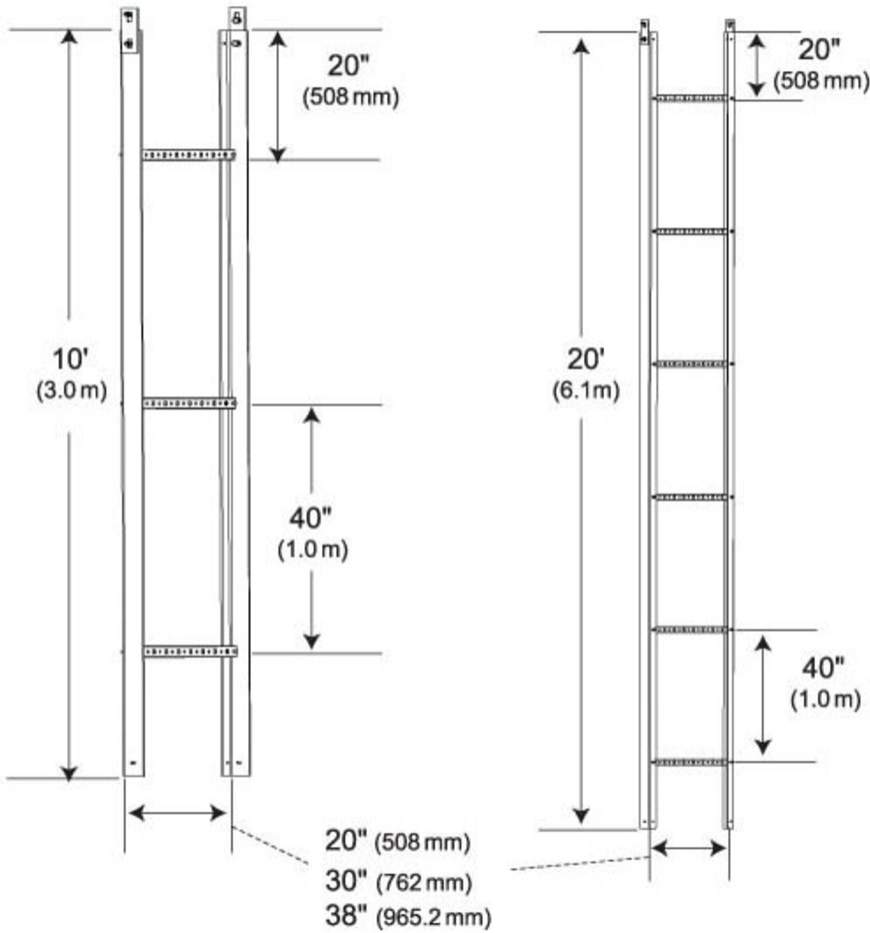

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Attachment kits | Ladder | Splice plates

Packaging quantity 1

Weight, net 55.1 kg | 121.475 lb

Regulatory Compliance/Certifications

Agency **Classification**

CL-1220-U

| | |
|---------------|--------------------------------------------------------------------------------|
| CHINA-ROHS | Above maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |



Included Products

- HK-CL-U – Universal Cable Ladder Hardware Kit for 1 in to 4-1/2 in round or angle members