


CS-BL-2

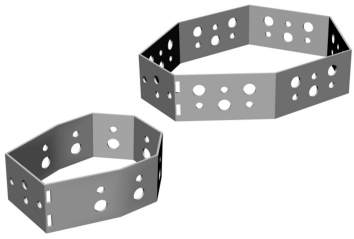

Cluster Support Bracket, large version, 2 in to 5 in OD round member attachment

Product Classification

Product Type Support bracket

General Specifications

Cable Runs, quantity 18

Hole, quantity 18

Mounting Cluster support

Dimensions

Height 127 mm | 5 in

Width 381 mm | 15 in


Length 279.4 mm | 11 in

Pipe Outer Diameter 60.96 mm | 2.4 in

Hole Size 3/4 in | 7/16 in

CS-BL-2

Outline Drawing

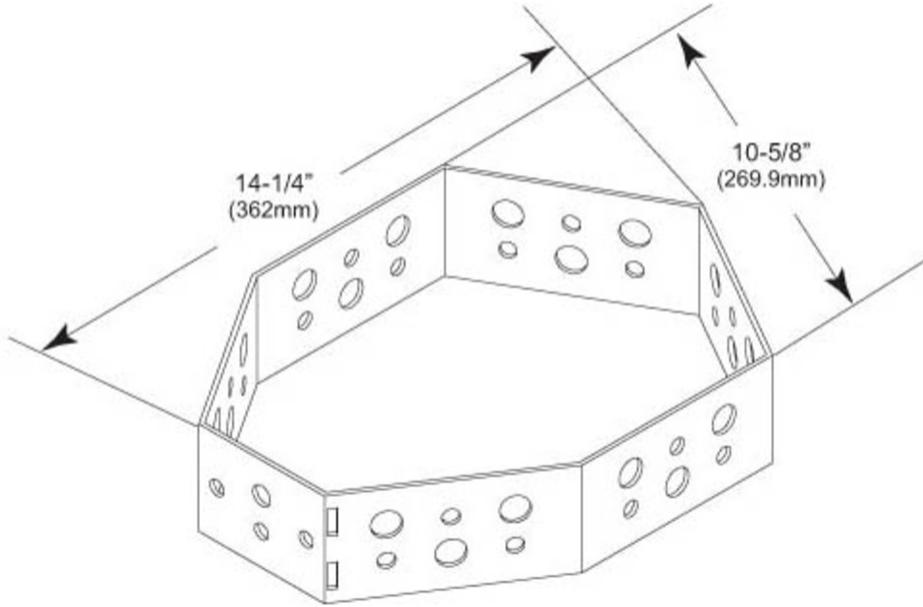

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Brackets
Packaging quantity 1
Weight, net 2.3 kg | 5.071 lb

Regulatory Compliance/Certifications

Agency **Classification**
ISO 9001:2015 Designed, manufactured and/or distributed under this quality management system



Included Products

CS-BL – Cluster Support Bracket, large version, angle member


CS-BL-2

attachment

GUB-4240

- Galvanized U-bolt Assembly, 1/2 in x 2-1/2 in x 4 in

CS-BL

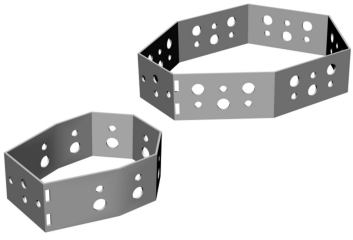

Cluster Support Bracket, large version, angle member attachment

Product Classification

Product Type Support bracket

General Specifications

Cable Runs, quantity 18

Hole, quantity 18

Mounting Cluster support

Dimensions

Height 127 mm | 5 in

Width 381 mm | 15 in


Length 279.4 mm | 11 in

Pipe Outer Diameter 60.96 mm | 2.4 in

Hole Size 3/4 in | 7/16 in

CS-BL

Outline Drawing

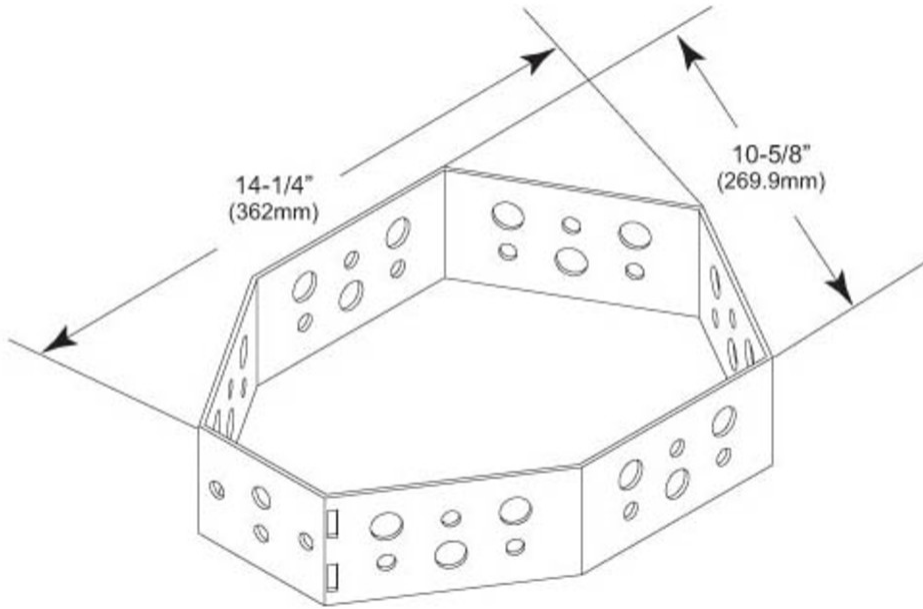

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights


Included Brackets
Packaging quantity 1
Weight, net 1.8 kg | 3.968 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant



GUB-4240

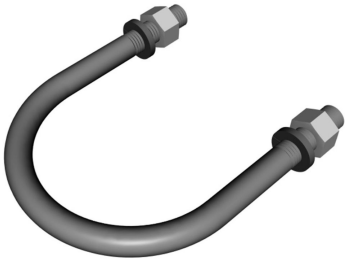

Galvanized U-bolt Assembly, 1/2 in x 2-1/2 in x 4 in

Product Classification

Product Type U-bolt

Dimensions

Height 101.6 mm | 4 in

Width 25.4 mm | 1 in

Length 101.6 mm | 4 in

Pipe Outer Diameter 12.7 mm | 0.5 in

Throat Dimension 63.5 mm | 2.5 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Nuts | U-bolts | Washers

Packaging quantity 1

Weight, net 0.3 kg | 0.661 lb

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant



