


# CS-PWRCN

---

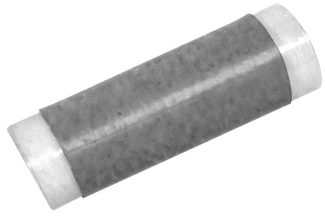

Cold shrink kit for Ericsson RRU power connector or 3/8" cable with 4.3-10 connector to device with 4.3-10 connector

## Product Classification

<b>Product Type</b>	Cold shrink kit
<b>Product Brand</b>	HELIAX®
<b>Ordering Note</b>	CommScope® standard product (Global)

## General Specifications

<b>Application</b>	Protects connector from corrosion
<b>Applications per Kit</b>	One 1/2 in–7/8 in
<b>Cable Family</b>	AL5-50   AVA5-50   FSJ4-50B   FSJ4-75A   LDF4-50A   LDF4-75   LDF5-50A   LDF5-75   VXL5-50
<b>Color</b>	Gray

## Dimensions

<b>Length</b>	152.4 mm   6 in
<b>Cable Diameter for Seal, maximum</b>	12.7 mm   0.5 in
<b>Cable Diameter for Seal, minimum</b>	9.65 mm   0.38 in
<b>Nominal Size</b>	1/2 in

## Material Specifications

<b>Material Type</b>	Silicone rubber
----------------------	-----------------

## Environmental Specifications

<b>UV Resistance Test Method</b>	UV condensation reference ASTM-G-53, light source UVA 340 fluorescent lamp
<b>UV Resistance, minimum with no degradation</b>	≥2000 hours
<b>Weather Resistance Test Method</b>	04AS00-03.6.0   IEC 60529:2001, IP67   MIL-STD-1344A, Method 1002

## Packaging and Weights

# CS-PWRCN

---

<b>Height, packed</b>	50.8 mm   2 in
<b>Width, packed</b>	50.8 mm   2 in
<b>Length, packed</b>	177.8 mm   7 in
<b>Included</b>	One Silicone Rubber Tube
<b>Packaging quantity</b>	1
<b>Weight, gross</b>	0.08 kg   0.176 lb

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

