

# GB-03165

---



Galvanized Bolt Kit, Grade 5, 3/8 in x 1-3/4 in

## Product Classification

**Product Type** Bolt kit

## Dimensions

**Height** 25.4 mm | 1 in

**Width** 25.4 mm | 1 in

**Length** 45.72 mm | 1.8 in

**Pipe Outer Diameter** 10.16 mm | 0.4 in

## Material Specifications

**Material Type** Hot dip galvanized steel

**Material Grade** Grade 5

## Packaging and Weights

**Included** Bolts | Nuts | Washers

**Packaging quantity** 1

## Regulatory Compliance/Certifications


| Agency        | Classification   |
|---------------|--|
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |

## Included Products

- GN-03 – Galvanized Hex Nut, 3/8 in
- GWL-03 – Galvanized Lock Washer, 3/8 in

# GN-03

---

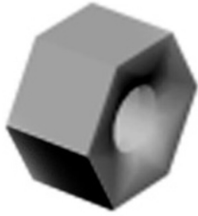

Galvanized Hex Nut, 3/8 in

## Product Classification

**Product Type** Nut

## Dimensions

**Height** 25.4 mm | 1 in

**Width** 25.4 mm | 1 in

**Length** 25.4 mm | 1 in

**Inner Diameter** 10.16 mm | 0.4 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Packaging and Weights

**Included** Nuts

**Packaging quantity** 1

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |



# GWL-03

---



Galvanized Lock Washer, 3/8 in

## Product Classification

**Product Type** Washer

## Dimensions

**Height** 25.4 mm | 1 in

**Width** 25.4 mm | 1 in

**Length** 25.4 mm | 1 in

**Inner Diameter** 10.16 mm | 0.4 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Packaging and Weights

**Included** Washers

**Packaging quantity** 1

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |

