


# SEC3-A5A1B3BA000

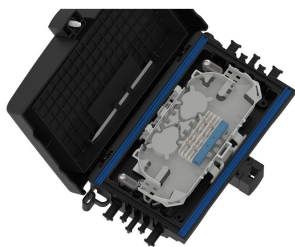

NOVUX™ SEC Closure, splice only, no adapters, 1x factory-installed 1:4 bare splitter, mounting included, black

- Design optimized for FTTH façade applications with gray and black colors
- Agnostic to connectivity technologies: splice, connector, field-installable connector for agility and flexibility
- Innovative removable hinge design allows cover to open from the left, right, or top
- Identification plate for either QR code or customer logo
- QR code and CommScope cTrak® app for one-click access to all product information

## Product Classification

Regional Availability	EMEA
Regional Availability Note	Contact your local CommScope representative for specific availability
Product Type	In-line, rectangular fiber closure
Product Brand	NOVUX™
Product Series	SEC100

## General Specifications

Cable Capacity, Branch	2 Round 1.8–7.0 mm (0.07–0.27 in)
Cable Capacity, Drop	6 Round 1.8–7.0 mm (0.07–0.27 in)
Cable Capacity, Feeder	2 Round 9.0–12.0 mm (0.35–0.47 in)
Cable Ports Quantity, total	10 round ports
Cable Sealing Type	Gasket/grommet configuration
Closure Sealing Type	Hinged with lock
Closure Style	In-line
Color	Black
Mounting	Facade   Wall
Network Area Type	Drop
Port Type	No adapter   No adapter
Splice Tray Included, quantity	1
Splice Tray Type Included	8-way, heat shrink
Splices per Tray, quantity	12
Splicing Capacity, maximum	8


# SEC3-A5A1B3BA000

Splicing Capacity, Single Fusion, maximum	8
Splicing Type, Supported	Single fusion
Split Ratio	Symmetrical
Splitter Type	1 x 4
Splitter, quantity	1

## Dimensions

Height	117 mm   4.606 in
Width	210 mm   8.268 in
Depth	50 mm   1.969 in

## Ordering Tree

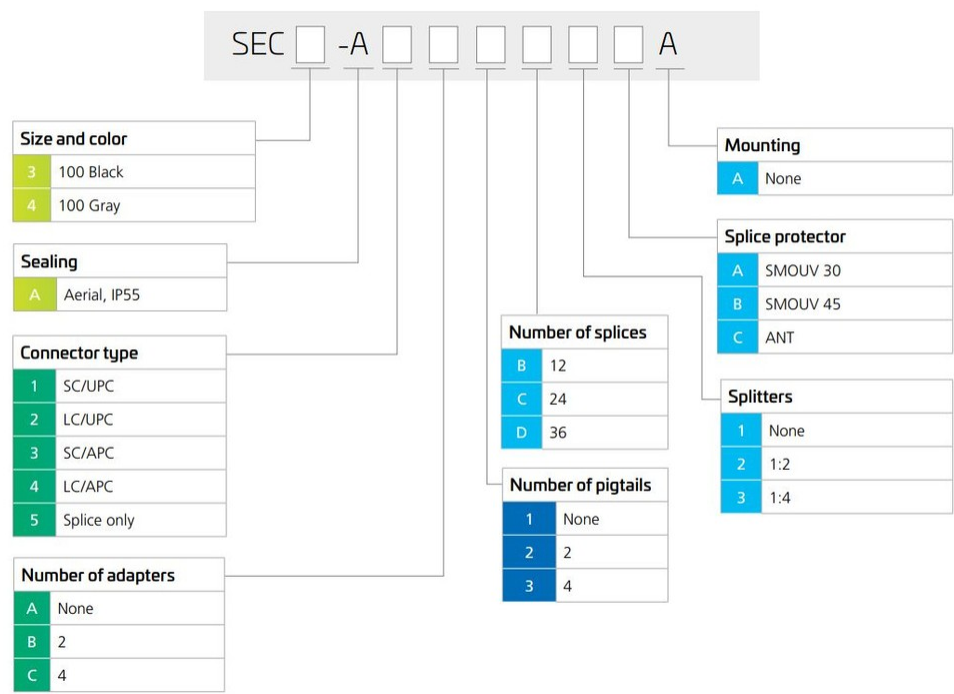

## Optical Specifications

Fiber Type	G.657.A1   G.657.A2   G.657.B3
------------	--------------------------------

## Environmental Specifications

Environmental Space	Facade   Outdoor
Qualification Standards	IP55

# SEC3-A5A1B3BA000

UV Resistance

UV stabilized

## Packaging and Weights

Included

1x factory-installed 1:4 bare splitter

Packaging quantity

1

Packaging Type

Box | Carton

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

