


RR-HFBP5

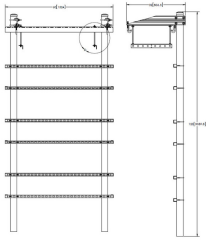

Remote Radio H-Frame, 5' Wide w/ Burial posts

Product Classification

Product Type Remote radio head unit mount


Dimensions

Height 3048 mm | 120 in

Width 1524 mm | 60 in

Length 812.8 mm | 32 in

Outline Drawing

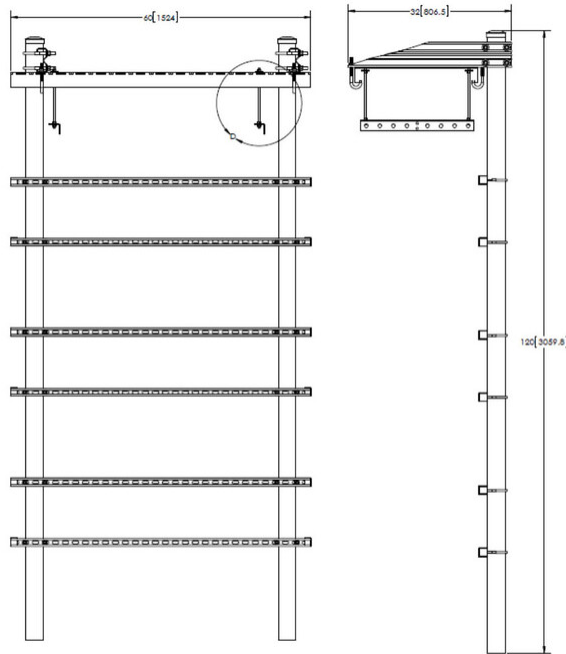

Material Specifications

Material Type Hot dip galvanized steel

RR-HFBP5

Packaging and Weights

Included Hardware | Legs | Unistrut

Packaging quantity 1

Weight, net 135.2 kg | 298.065 lb

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

Included Products

MF-130 – Direct Burial Pipe Column, 13 ft 4 in

MF-130



Direct Burial Pipe Column, 13 ft 4 in

Product Classification

Product Type Pipe column

General Specifications

Application Direct burial

Mounting Waveguide bridge support bracket

Pipe, quantity 1

Dimensions

Height 4064 mm | 160 in

Width 88.9 mm | 3.5 in


Length 88.9 mm | 3.5 in

Pipe Length 4,053.84 mm | 159.6 in

Pipe Outer Diameter 88.9 mm | 3.5 in

MF-130

Outline Drawing

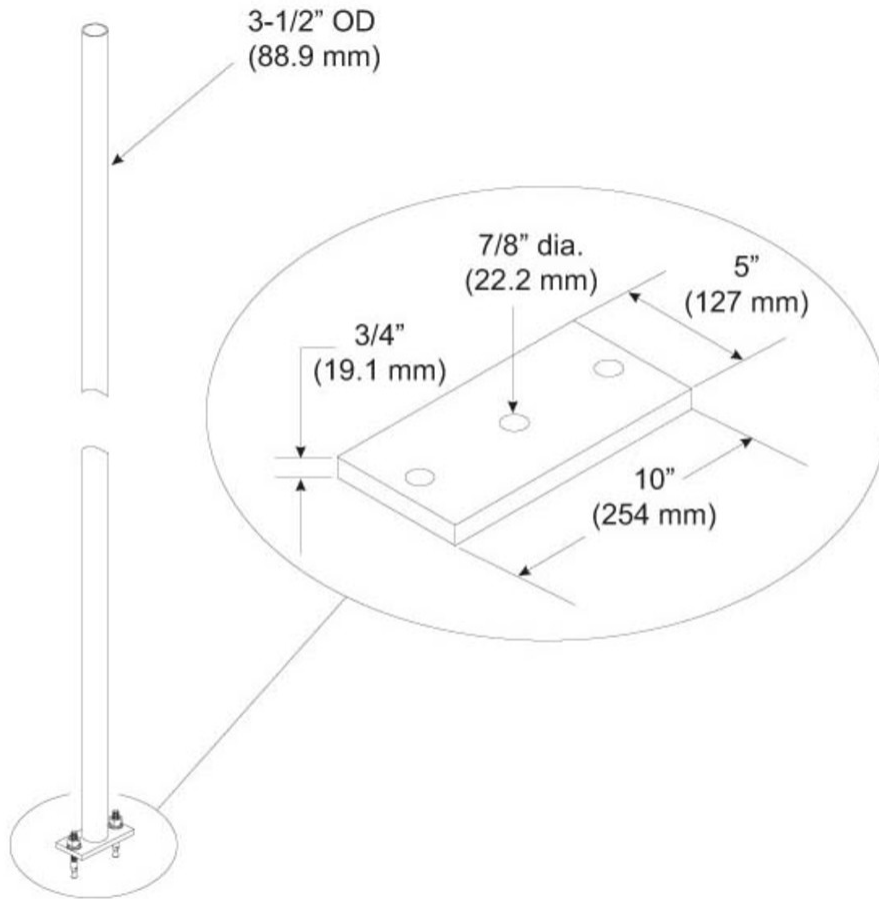

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Anchors | Pipe

Packaging quantity 1

Weight, net 45.8 kg | 100.972 lb

Regulatory Compliance/Certifications

Agency **Classification**

MF-130

CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

