


UKXMXMXAK

Base Product

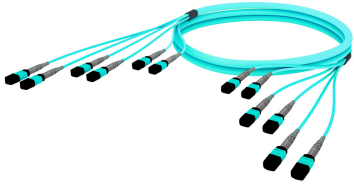

Ultra Low Loss (ULL) Multimode OM4 MPO12 (Pinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 72-Fiber, Low Smoke Zero Halogen (LSZH)

This product will be discontinued on: April 30, 2024

Replaced By:

UKXMXMXCK

Ultra Low Loss (ULL) OM4 MPO12 UPC (pinned) to MPO12 UPC (pinned) Fiber Trunk Cable Assembly, 192-Fiber, Armored Indoor Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada

General Specifications

Connector A, quantity	6
Color, boot A	Black
Color, connector A	Aqua
Connector B, quantity	6
Color, boot B	Black
Color, connector B	Aqua
Construction Type	Armored Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Male
Interface Feature, connector A	Pinned
Interface, Connector B	MPO-12/UPC Male
Interface Feature, connector B	Pinned
Jacket Color	Aqua

UKXMXMXAK

Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	72

Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

760120089 N-072-MZ-5K-F12AQ	-	Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Multimode OM4, 72 fiber multi-unit with 12 fiber subunits, Gel-free, Feet jacket marking, Aqua jacket color
860366228	-	MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm