


SS-TB2550

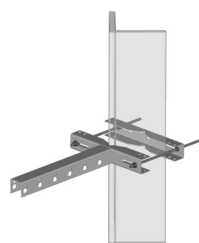

Star Support Tee Bracket for 1-1/2 in to 5-9/16 in OD round members and 2-1/2 in to 5 in angle members

Product Classification

Product Type Star Support Bracket

General Specifications


Cable Runs, quantity	12
Hole, quantity	12
Mounting	Angle members, 63.5–127 mm (2-1/2 in to 5 in) Round member, 38.1–141.29 mm (1-1/2 in to 5-9/16 in) OD

Dimensions

Height	101.6 mm 4 in
Width	304.8 mm 12 in
Length	254 mm 10 in
Mounting Diameter 2, maximum	127 mm 5 in
Mounting Diameter 2, minimum	63.5 mm 2.5 in
Mounting Diameter, maximum	142.24 mm 5.6 in
Mounting Diameter, minimum	38.1 mm 1.5 in
Hole Size	3/4 in 7/16 in

SS-TB2550

Outline Drawing

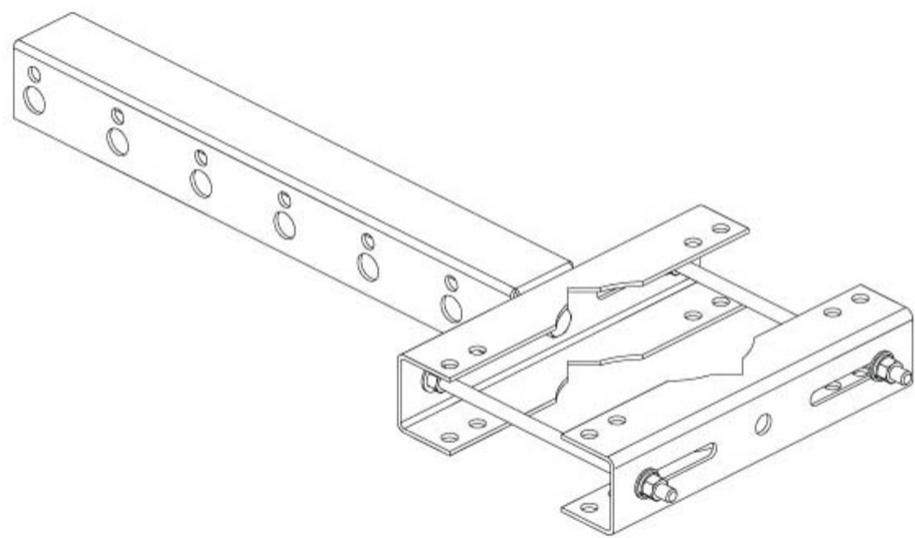

Material Specifications

Material Type	Hot dip galvanized steel
----------------------	--------------------------

Packaging and Weights


Included	Brackets
Packaging quantity	1
Weight, net	3.6 kg 7.937 lb

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.andrew.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

Included Products

SS-TB	– Star Support Tee Bracket
-------	----------------------------

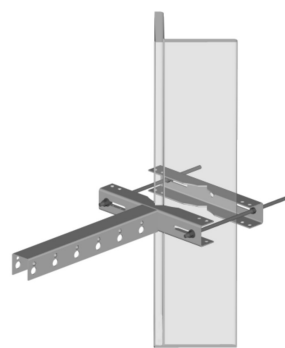

Star Support Tee Bracket

Product Classification

Product Type Support bracket

General Specifications

Hole, quantity 12

Mounting Round and angle legs

Dimensions

Height 101.6 mm | 4 in


Width 304.8 mm | 12 in

Length 254 mm | 10 in

Hole Size 3/4 in | 7/16 in

SS-TB

Outline Drawing

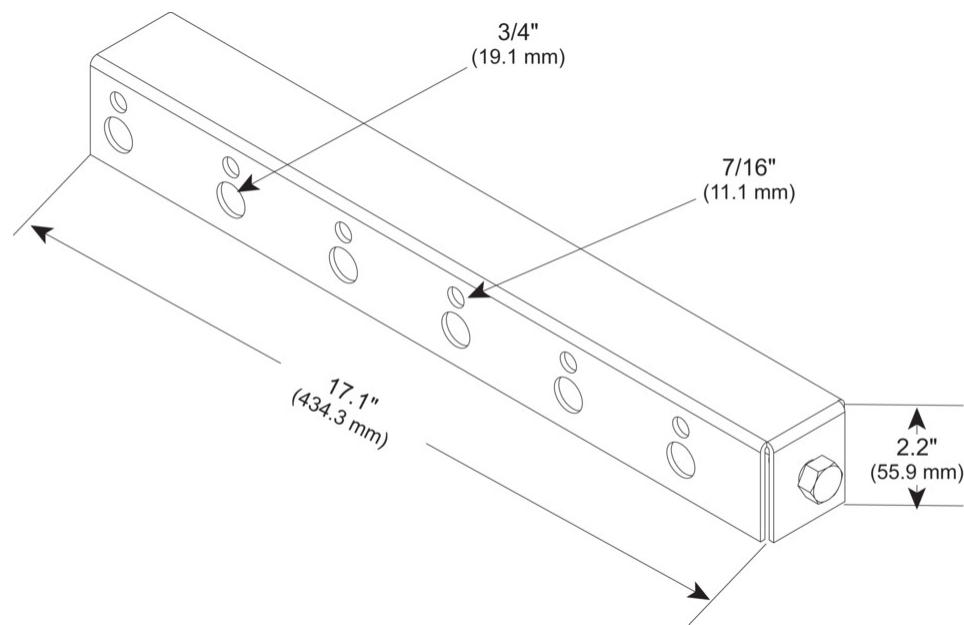

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Brackets

Packaging quantity 1

Weight, net 1.4 kg | 3.086 lb