


F4WLCUCAK

Base Product

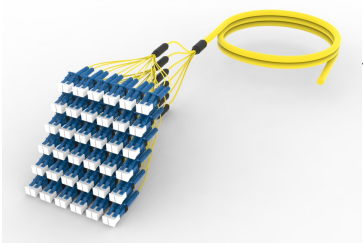

TeraSPEED® LC/UPC to LC/UPC, InstaPATCH® 360 Ruggedized Fanout Cable, 72-Fiber, LSZH

Product Classification

Regional Availability	Europe Middle East/Africa
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada

General Specifications


Color, connector A	Blue
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	LC/UPC
Interface, Connector B	Unterminated
Fibers per Subunit, quantity	12
Total Fibers, quantity	72

Dimensions

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	7 – 999

Ordering Tree

F4WLCUCAK

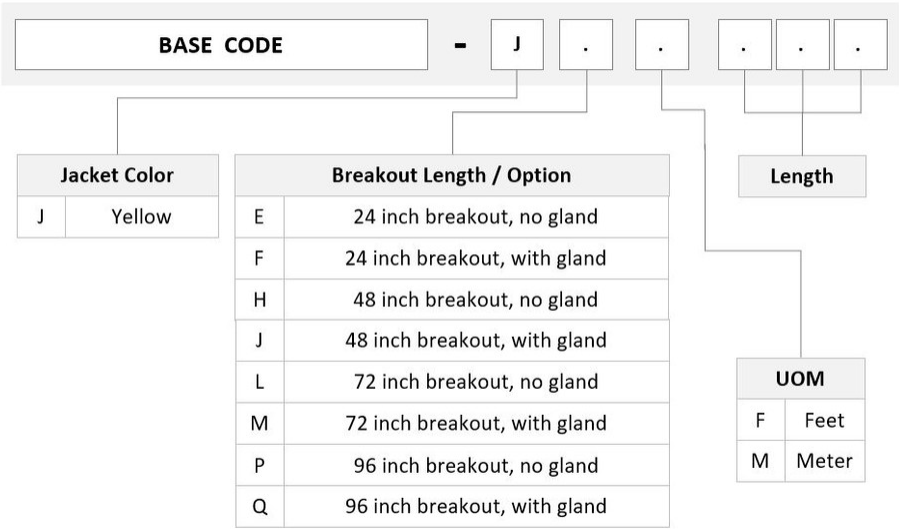

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode
Fiber Type G.652.D | G.657.A1, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Indoor | Low Smoke Zero Halogen (LSZH)

Included Products

- 460125206 – TeraSPEED® Pre-Radiused LC Connector duplex for 1.6 mm Fiber, Singlemode
- 760239612 – Fiber indoor cable, TeraSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 24 fibers, 12 fiber subunits, Singlemode G.652.D and G.657.A1, Gel-free, Feet jacket marking, Yellow jacket color, B2ca Flame rating
- N-024-MP-8W-F12YL/B2