


UQGQPQXHF

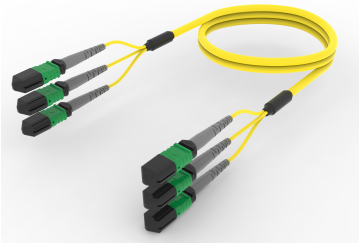

Ultra Low Loss (ULL) Singlemode, MPO/8(Unpinned) to MPO/8(Pinned), 24-Fiber, Plenum, array cord

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America |
| Portfolio | CommScope® |
| Product Type | Fiber array cable assembly |
| Product Brand | SYSTIMAX ULL |
| Ordering Note | For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration |

General Specifications

| | |
|---------------------------------------|-------------------------|
| Connector A, quantity | 3 |
| Color, boot A | Gray |
| Color, connector A | Green |
| Connector B, quantity | 3 |
| Color, boot B | Gray |
| Color, connector B | Green |
| Construction Type | Stranded |
| Furcation Color | Yellow |
| Interface, Connector A | MPO-08/APC Female |
| Interface Feature, connector A | Unpinned |
| Interface, Connector B | MPO-08/APC Male |
| Interface Feature, connector B | Pinned |
| Jacket Color | Yellow |
| Polarity | Method B Enhanced (ULL) |
| Fibers per Subunit, quantity | 8 |
| Total Fibers, quantity | 24 |


UQGQPQXHF

Dimensions

Cable Assembly Length Range (m) 1 – 305

Cable Assembly Length Range (ft) 1 – 999

Ordering Tree

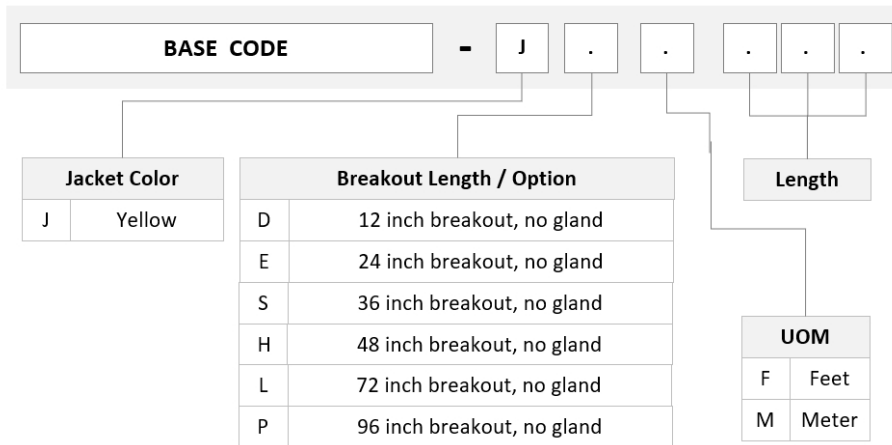

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|--|
| ANATEL | Compliant |
| CHINA-ROHS | Above maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |

UQGQPQXHF

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted



Included Products

- 760245873
P-024-MP-8G1-F36YL – Fiber indoor cable, Plenum for MPO Light Duty Patchcords, 24 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color
- 860637705 – MPO8, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm
- 860637706 – MPO8, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm