


Base Product

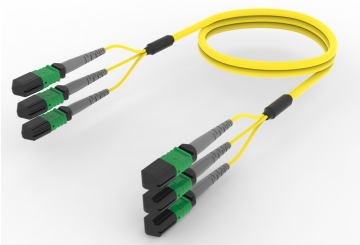

Ultra Low Loss (ULL) Singlemode, MPO/8(Unpinned) to MPO/8(Pinned), 24-Fiber,Plenum,array cord

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Connector A, quantity	3
Color, boot A	Gray
Color, connector A	Green
Connector B, quantity	3
Color, boot B	Gray
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-08/APC Female
Interface Feature, connector A	Unpinned
Interface, Connector B	MPO-08/APC Male
Interface Feature, connector B	Pinned
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	24

UQGQPQXHF

Dimensions

Cable Assembly Length Range (m)	1 – 305
Cable Assembly Length Range (ft)	1 – 999

Ordering Tree

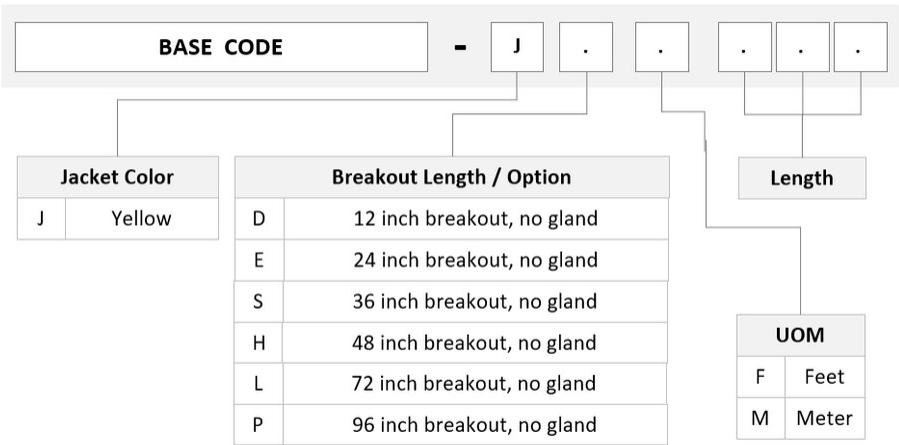

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
-----------------------------------	---------------------------------

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor Plenum

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

UQGQPQXHF

ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

760257038	–	Fiber indoor cable, Plenum for MPO Light Duty Patchcords, 24 fiber, Singlemode G.657.A2/B2,
P-024-MP-8G1-F30YL		Feet jacket marking, Yellow jacket color
860637705	–	MPO8, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm
860637706	–	MPO8, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm