


TW-N10

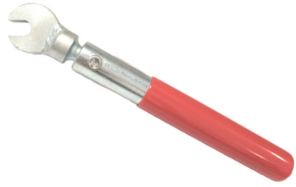

Torque Wrench for coupling torque of Nex10 connectors, 11 mm opening

Product Classification

Product Type	Wrench
Product Brand	HELIAX®
Ordering Note	CommScope® non-standard product

General Specifications

Application	Torques Nex10 connectors
Calibration	6 mo
Tool Type	Torque wrench

Dimensions

Wrench Opening	10.922 mm 0.43 in
-----------------------	---------------------

Material Specifications

Material Type	Steel
----------------------	-------

Mechanical Specifications

Torque Tolerance	-0/+2
Torque Value	13.32 in lb 1.505 N-m

Packaging and Weights

Height, packed	284.48 mm 11.2 in
Length, packed	279.4 mm 11 in
Packaging quantity	1
Weight, gross	0.89 kg 1.962 lb

Regulatory Compliance/Certifications

Agency	Classification
---------------	-----------------------

TW-N10

CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

