

HFT206-4SNOK6



HELIAX® Hybrid Cable Assembly. HQLC End 1: 4 fibers DLC for Nokia AirScale RRUs, R2CT with power connector pre-installed (red / black conductors). End 2: 4 fibers terminated LC and 2 X 6 AWG conductors terminated at hybrid trunk connector

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Product Type	Hybrid cable assembly
Product Brand	HELIAX®
Product Series	HFT
Ordering Note	ANDREW® non-standard product

General Specifications


Conductors, quantity	2
Construction Type	Hybrid standard tail
Interface, Connector A	DLC
Interface Feature, connector A	Uniboot
Interface Body Style, connector A	Straight
Interface, Connector B	HQ-LC
Interface Feature, connector B	Outdoor
Interface Body Style, connector B	Straight
Jacket Color	Black
Total Fibers, quantity	4

Dimensions

Cable Assembly Length Range (ft)	15 – 200
Diameter Over Jacket	18.31 mm 0.721 in
Center Conductor Gauge	6 AWG

Ordering Tree

HFT206-4SNOK6

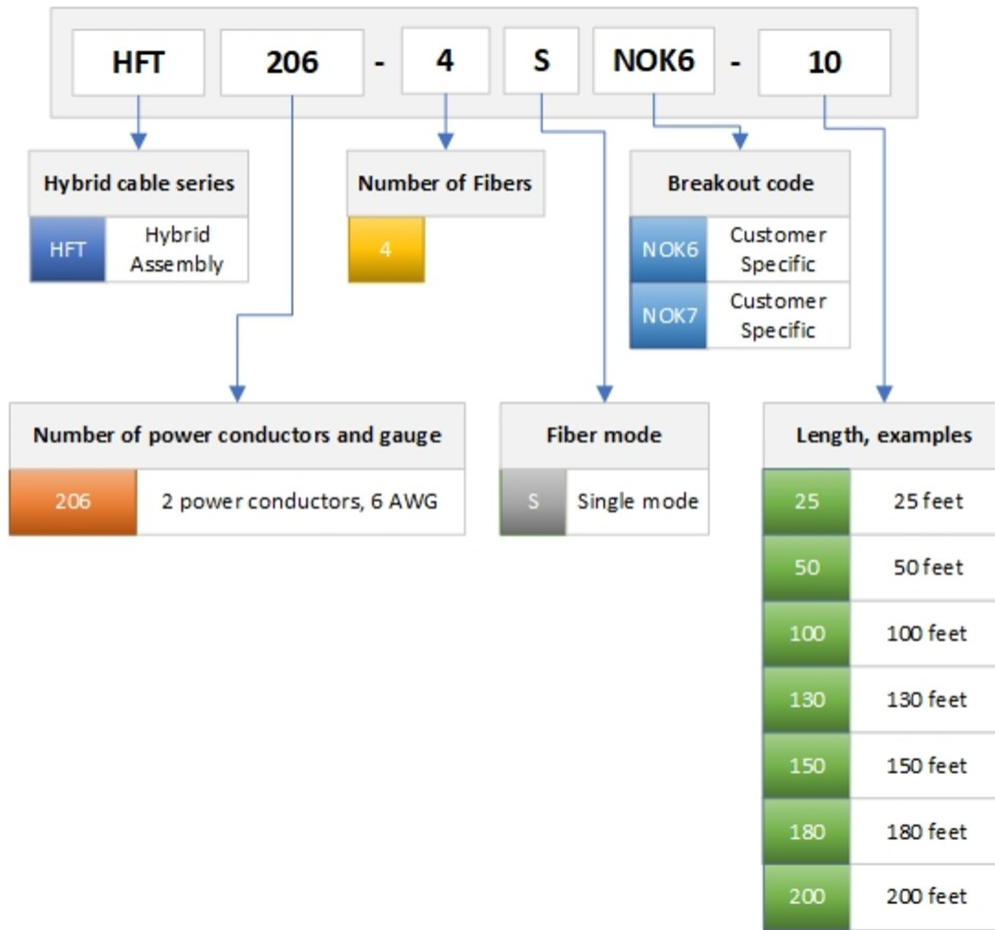

Mechanical Specifications

Minimum Bend Radius 221 mm | 8.701 in

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2

Insertion Loss, typical note Insertion loss is measured at 1310 and 1550 nm

Insertion Loss, typical 0.75

Environmental Specifications

Operating Temperature -40 °C to +75 °C (-40 °F to +167 °F)

Packaging and Weights

HFT206-4SNOK6

Cable weight 0.5 kg/m | 0.336 lb/ft

* Footnotes

Insertion Loss, typical note Insertion loss is measured at a room temp of +20°C (+68°F)