


IFC-7/0JA020-NG

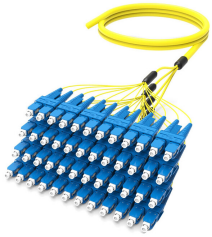

Fiber Optic Intra Facility Fiber Cable, OS2, SC/UPC to Stub, 20 m

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber distribution cable assembly
Product Series	IFC

General Specifications

Connector A, quantity	48
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	0
Interface, Connector A	SC/UPC
Interface, Connector B	Unterminated
Jacket Color	Yellow
Total Fibers, quantity	48

Dimensions

Cord Length	20 m 65.617 ft
--------------------	------------------

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS2
Insertion Loss, maximum, connector A	0.2 dB
Return Loss, minimum, connector A	55 dB

Environmental Specifications

Environmental Space	Riser
----------------------------	-------

Packaging and Weights

IFC-7/OJA020-NG

Packaging quantity

1

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

