


WK-CNT

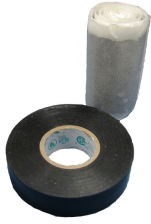

Weatherproofing Kit for Connectors and Splices, includes butyl rubber and PVC tape

Product Classification

| | |
|----------------------|---------------------------------|
| Product Type | Weatherproofing tape |
| Product Brand | HELIAX® |
| Ordering Note | CommScope® non-standard product |

General Specifications

| | |
|-----------------------------|--|
| Application | Provides additional moisture seal for cable connections |
| Applications per Kit | Four 0.195 in to 0.195 in Four 0.240 in to 0.240 in Three 0.300 in to 0.300 in Three 0.400 in to 0.300 in Three 0.400 in to 0.400 in Two 0.400 in to 0.600 in Two 0.600 in to 0.600 in |

Dimensions

| | |
|---------------------|--|
| Nominal Size | 0.195 in 0.240 in 0.300 in 0.400 in 0.600 in |
|---------------------|--|

Material Specifications

| | |
|----------------------|------------------------------|
| Material Type | Butyl rubber tape PVC tape |
|----------------------|------------------------------|

Environmental Specifications

| | |
|---|---|
| Operating Temperature | -10 °C to +80 °C (+14 °F to +176 °F) |
| UV Resistance Test Method | Butyl test method in QUV weatherometer cycle of 8 hours UV at 150 °F then 4 hours of condensation at 104 °F PVC tape test method UL 510, ASTM D1000 |
| UV Resistance, minimum with no degradation | ≥1000 hours |
| Weather Resistance Test Method | 04AS00-03.6.0 MIL-STD-1344A, Method 1002 |

Packaging and Weights

| | |
|-----------------------|-------------------|
| Height, packed | 165.1 mm 6.5 in |
| Width, packed | 50.8 mm 2 in |
| Length, packed | 91.44 mm 3.6 in |

WK-CNT

| | |
|---------------------------|--|
| Included | One roll of 2-1/2 in butyl rubber tape (0.06 in thick) One roll of 3/4 in PVC tape |
| Packaging quantity | 1 |
| Weight, gross | 0.36 kg 0.794 lb |

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| CHINA-ROHS | Below maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| ROHS | Compliant |
| UK-ROHS | Compliant |



Included Products

- 42615-10 – Butyl Rubber Tape, 24 in
- 9905-41 – Black 3/4 in PVC Tape, 66 ft