

DFJ-2S5-NBSC



HELIAX® Discrete, 2 single mode fiber, 5 mm LSZH cable. End 1: DLC with weatherproofing boot. End 2: SC

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Product Type	Wireless Fiber Cable Assemblies
Product Brand	HELIAX®
Product Series	DFJ
Ordering Note	ANDREW® non-standard product

General Specifications


Construction Type	Discrete fiber tail
Interface, Connector A	DLC
Interface Feature, connector A	Nokia boot
Interface Body Style, connector A	Straight
Interface, Connector B	SC/UPC
Interface Feature, connector B	Nokia boot
Interface Body Style, connector B	Straight
Jacket Color	Black
Total Fibers, quantity	2

Dimensions

Cable Assembly Length Range (m)	3 – 60
Diameter Over Jacket	4.8 mm 0.189 in

Ordering Tree

DFJ-2S5-EAS-10M

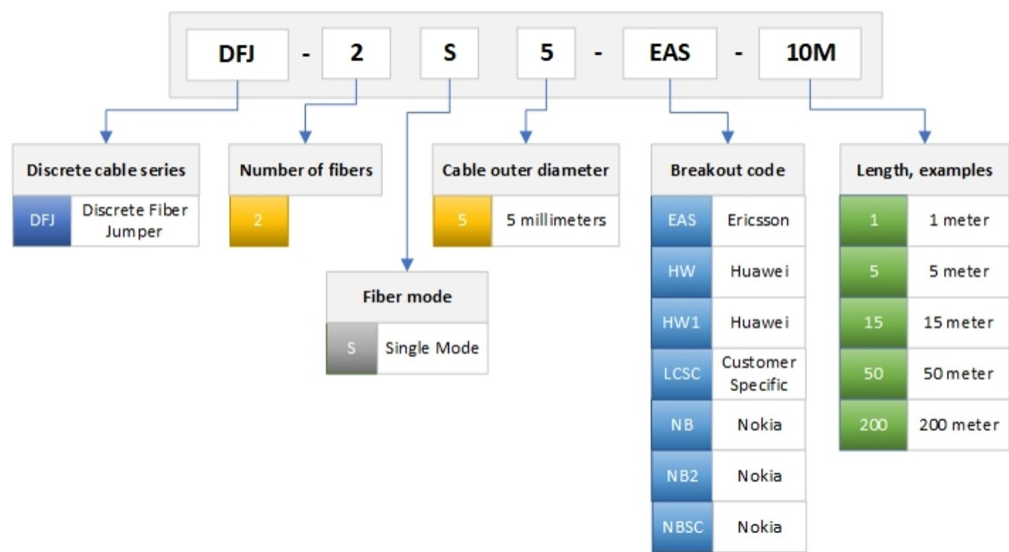

Material Specifications

Jacket Material Low Smoke Zero Halogen (LSZH)

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2

Insertion Loss, typical note Insertion loss is measured at 1310 and 1550 nm

Insertion Loss, typical 0.5

Environmental Specifications

Operating Temperature -40 °C to +80 °C (-40 °F to +176 °F)

Environmental Space Outdoor

Packaging and Weights

Cable weight 24 kg/km | 16.127 lb/kft

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

* Footnotes

Insertion Loss, typical note Insertion loss is measured at a room temp of +20°C (+68°F)

