


# 760249184

---

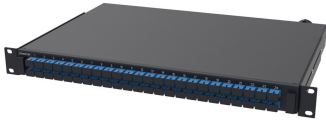

Fiber Optic Termination/Splice Panel, 1U, 19 in, 48 SC simplex adapter, singlemode, black

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   India |
| <b>Portfolio</b>             | CommScope®                                   |
| <b>Product Type</b>          | Fiber patch/splice panel                     |

## General Specifications

|  |                     |
|--|---------------------|
| <b>Functionality</b>                   | Patching   Splicing |
| <b>Body Style</b>                      | Symmetrical         |
| <b>Cable Exit Location</b>             | Rear                |
| <b>Color</b>                           | Black               |
| <b>Growth Configuration</b>            | Fully loaded        |
| <b>Interface, front</b>                | SC/UPC              |
| <b>Rack Type</b>                       | EIA 19 in           |
| <b>Rack Units</b>                      | 1                   |
| <b>Shelf Movement</b>                  | Sliding             |
| <b>Splice Trays Included, quantity</b> | 0                   |
| <b>Total Ports, quantity</b>           | 48                  |

## Dimensions

|               |                    |
|---------------|--------------------|
| <b>Height</b> | 44.45 mm   1.75 in |
| <b>Width</b>  | 482.6 mm   19 in   |
| <b>Depth</b>  | 320 mm   12.598 in |

## Material Specifications

|                      |               |
|----------------------|---------------|
| <b>Finish</b>        | Powder coated |
| <b>Material Type</b> | Steel         |

## Optical Specifications

# 760249184

---

**Fiber Mode** Singlemode

## Packaging and Weights

**Included** Mounting hardware

**Packaging quantity** 1