


# ARGMPLUGD

## Base Product

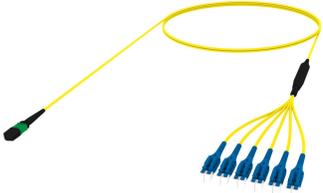

Singlemode MPO12 (Unpinned) to LC/UPC Uniboot, Array Cord, 12-Fiber, Low Smoke Zero Halogen

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber array cable assembly

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Color, boot A

Black

### Color, connector A

Green

### Color, boot B

Blue

### Color, connector B

Blue

### Construction Type

Stranded

### Furcation Color

Yellow

### Interface, Connector A

MPO-12/APC Female

### Interface Feature, connector A

Unpinned

### Interface, Connector B

LC/UPC

### Interface Feature, connector B

Uniboot

### Jacket Color

Yellow

### Polarity

Method A

### Fibers per Subunit, quantity

12

### Total Fibers, quantity

12

## Dimensions

### Cable Assembly Length Range (m)


1 – 305

### Cable Assembly Length Range (ft)

1 – 999

# ARGMPLUGD

## Ordering Tree

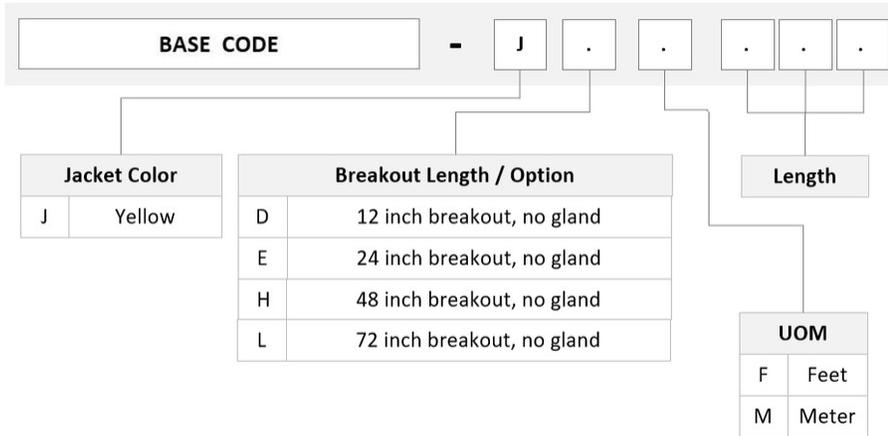

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Singlemode  
**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)  
**Environmental Space** Dual Rated LSZH/Riser | Indoor

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# ARGMPLUGD

---



## Included Products

- |                                   |   |   |
|-----------------------------------|---|---|
| 760237972<br>N-012-MP-8G1-F30YL/D | - | Fiber Indoor Cable, Low Smoke Zero Halogen Riser Light Duty MPO Patchcord Cable, 12 fiber, gel-free, singlemode G.657.A2/B2, feet jacket marking, yellow cable jacket color, Dca Flame Rating |
| 860638318                         | - | MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm   |
| 860650412                         | - | TeraSPEED® LC UniBoot 2.0MM UPC/LC UNIBOOT CONNECTOR KIT  |