


# FFXLCLC21

Base Product

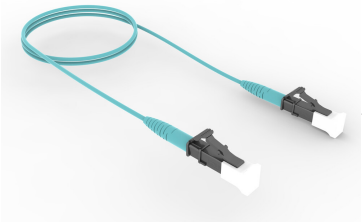

OM4 LC/UPC to LC/UPC, Fiber Patch Cord, 1.6 mm Simplex, Low Smoke Zero Halogen (LSZH)

## Product Classification

|                       |  |
|-----------------------|--|
| Regional Availability | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America               |
| Portfolio             | CommScope®   |
| Product Type          | Fiber patch cord, simplex  |
| Product Brand         | SYSTIMAX InstaPATCH® 360   |
| Product Series        | FFX  |
| Ordering Note         | For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                        |        |
|------------------------|--------|
| Color, boot A          | Aqua   |
| Color, connector A     | Black  |
| Color, boot B          | Aqua   |
| Color, connector B     | Black  |
| Interface, Connector A | LC/UPC |
| Interface, Connector B | LC/UPC |
| Jacket Color           | Aqua   |
| Total Fibers, quantity | 1      |

## Dimensions

|                                  |                   |
|----------------------------------|-------------------|
| Cable Assembly Length Range (m)  | 1 – 999           |
| Cable Assembly Length Range (ft) | 1 – 999           |
| Diameter Over Jacket             | 1.6 mm   0.063 in |

## Mechanical Specifications

|                                   |                                 |
|-----------------------------------|---------------------------------|
| Cable Retention Strength, maximum | 11.24 lb @ 0 °   4.40 lb @ 90 ° |
|-----------------------------------|---------------------------------|

# FFXLCLC21

## Optical Specifications

|            |                 |
|------------|-----------------|
| Fiber Mode | Multimode       |
| Fiber Type | OM4, LazrSPEED® |

## Environmental Specifications

|                       |                                      |
|-----------------------|--------------------------------------|
| Operating Temperature | -10 °C to +60 °C (+14 °F to +140 °F) |
| Environmental Space   | Dual Rated LSZH/Riser                |

## Packaging and Weights

|                    |   |
|--------------------|---|
| Packaging quantity | 1 |
|--------------------|---|

## Regulatory Compliance/Certifications

|        |                |
|--------|----------------|
| Agency | Classification |
| ANATEL | Compliant      |



## Included Products

|                     |   |   |
|---------------------|---|---|
| 760164152           | – | Fiber Indoor Cable, LazrSPEED® 1.6mm Low Smoke Zero Halogen Riser, 1-fiber Simplex, |
| N-001-SP-5K-F16AQ/E |   | Multimode OM4, Feet jacket marking, Aqua jacket color, Eca Flame Rating             |
| 860655461           | – | LC/UPC Connector, Multimode, Aqua   |