


760018820

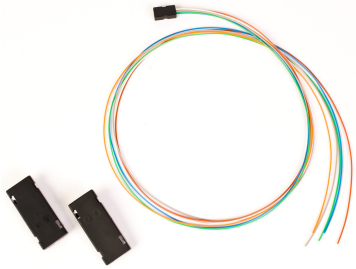

6 Fiber Breakout Kit, loose tube, 900 μm

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	SYSTIMAX®
Product Type	Fiber breakout kit, rectangular

General Specifications

Color	Black
Compatible Interface	LC LC, keyed SC ST

Dimensions

Height	7.62 mm 0.3 in
Width	17.78 mm 0.7 in
Length	43.18 mm 1.7 in
Tube Length	609.6 mm 24 in
Tube Inner Diameter	500 μm
Tube Outer Diameter	900 μm

Material Specifications

Material Type, body	Acrylonitrile butadiene styrene (ABS)
Material Type, tubing	Thermoplastic elastomer (TPE)

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
------------------------------	--------------------------------------

Packaging and Weights

Included	Breakout unit Instruction sheet Six buffer tubes, 24 in x 900 μm Snap together housing
Packaging quantity	1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

