


BLK-RCT-B09D0

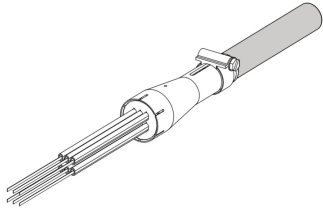

Fiber Optic Ribbon Breakout Kit, 24F/ribbon, 240-432F/tube, 11-15 mm central tube outside dia., 9 tubes/leg

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber breakout kit, rectangular
Product Series	BLK-R

General Specifications

Application	For use with ribbon fiber cables
Breakout Legs, quantity	1
Fibers per Ribbon, maximum	24
Fibers per Tube, maximum	672
Tube Type	Ribbon central tube
Tubes per Leg, quantity	9

Dimensions

Tube Length	5,001.26 mm 196.9 in
Central Tube Outer Diameter	11 mm – 15 mm (0.43 in – 0.60 in)

Environmental Specifications

Environmental Space	Outdoor
----------------------------	---------

Packaging and Weights

Packaging quantity	1
Packaging Type	Bag Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

BLK-RCT-B09D0

ROHS

Compliant

UK-ROHS

Compliant

