


BLK-RCT-B36E0

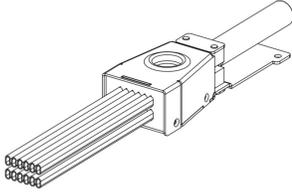

Fiber Optic Ribbon Breakout Kit, 24F/ribbon, 576/720/864F/tube, 15-20 mm central tube out. dia., 36 tubes/leg

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber breakout kit, rectangular
Product Series	BLK-R

General Specifications

Application	For use with ribbon fiber cables
Breakout Legs, quantity	1
Fibers per Ribbon, maximum	24
Fibers per Tube, maximum	2160
Tube Type	Ribbon central tube
Tubes per Leg, quantity	36

Dimensions

Tube Length	5,001.26 mm 196.9 in
Central Tube Outer Diameter	15 mm – 20 mm (0.60 in – 0.80 in)

Environmental Specifications

Environmental Space	Outdoor
----------------------------	---------

Packaging and Weights

Packaging quantity	1
Packaging Type	Bag Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

BLK-RCT-B36E0

ROHS

Compliant

UK-ROHS

Compliant

