

UHVMPMXAG

Base Product



Ultra Low Loss (ULL) Multimode OM5 MPO12 (Unpinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 36-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	3
Color, boot A	Black
Color, connector A	Lime green
Connector B, quantity	3
Color, boot B	Black
Color, connector B	Lime green
Construction Type	Armored Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-12/UPC Female
Interface Feature, connector A	Unpinned
Interface, Connector B	MPO-12/UPC Male
Interface Feature, connector B	Pinned
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)


UHVMPMXAG

Fibers per Subunit, quantity	12
Total Fibers, quantity	36

Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

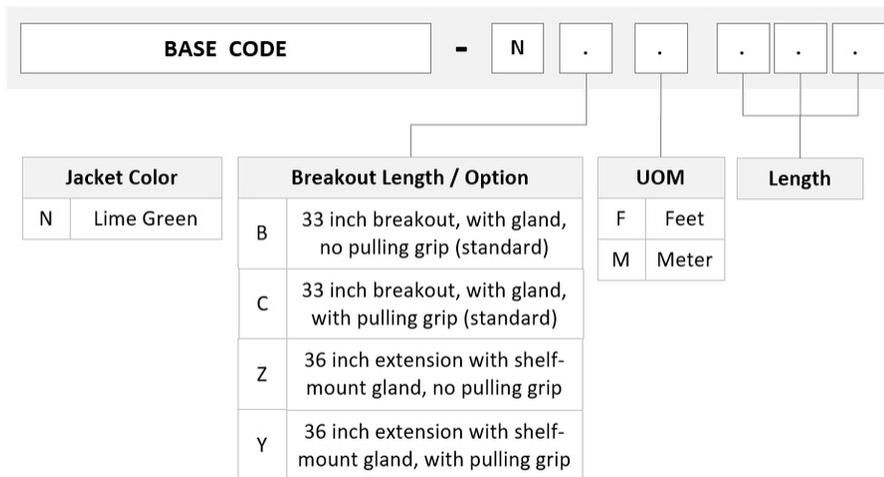

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM5, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor Plenum

Included Products

760230227	-	Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, interlocking aluminum armored with
-----------	---	---

UHVMPMXAG

P-036-MZ-5G-F12LM		plenum jacket, Multimode OM5, 36 fiber multi-unit with 12 fiber subunits, Lime-green jacket color, Feet cable marking
860617232	-	MPO12, ULTRA LOW LOSS, FEMALE, OM5, LIME, 3mm
860617240	-	MPO12, ULTRA LOW LOSS, MALE, OM5, LIME, 3mm