


R-DN

Base Product

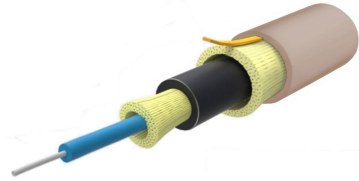

Fiber Optic Cable, Indoor/Outdoor Riser, Drop Dielectric

- Indoor/outdoor cables are tough enough for outdoor use while also being listed for indoor use
- Superior mechanical and optical performance with unmatched stability and quality

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber indoor/outdoor cable
Product Series	R-DN

General Specifications

Construction Type	Non-armored
Subunit Type	Gel-free

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Environmental Space	Riser

* Footnotes

Operating Temperature Specification applicable to non-terminated bulk fiber cable