

MPJ2DBBGNN3M



HELIAX® Modular Remote Radio Head Power Cable Assembly, 2 conductors Black/Blue 10mm², Blunt Cut to OEC GEN; CPR rated Cca s1, d1, a1. 3 meter

Product Classification

Regional Availability	Asia EMEA North America
Portfolio	CommScope®
Product Type	Power cable assembly
Product Brand	HELIAX®
Product Series	Modular
Ordering Note	CommScope® standard product (Global)

General Specifications


Cable Type	Power
Conductors, quantity	2
Construction Type	Non-armored
Jacket Color	Black

Dimensions

Cord Length	3 m 9.843 ft
Diameter Over Dielectric	4.724 mm 0.186 in
Diameter Over Jacket, nominal	16.789 mm 0.661 in
Center Conductor Gauge	10 mm ²

Ordering Tree

MPJ2DBBGNN3M

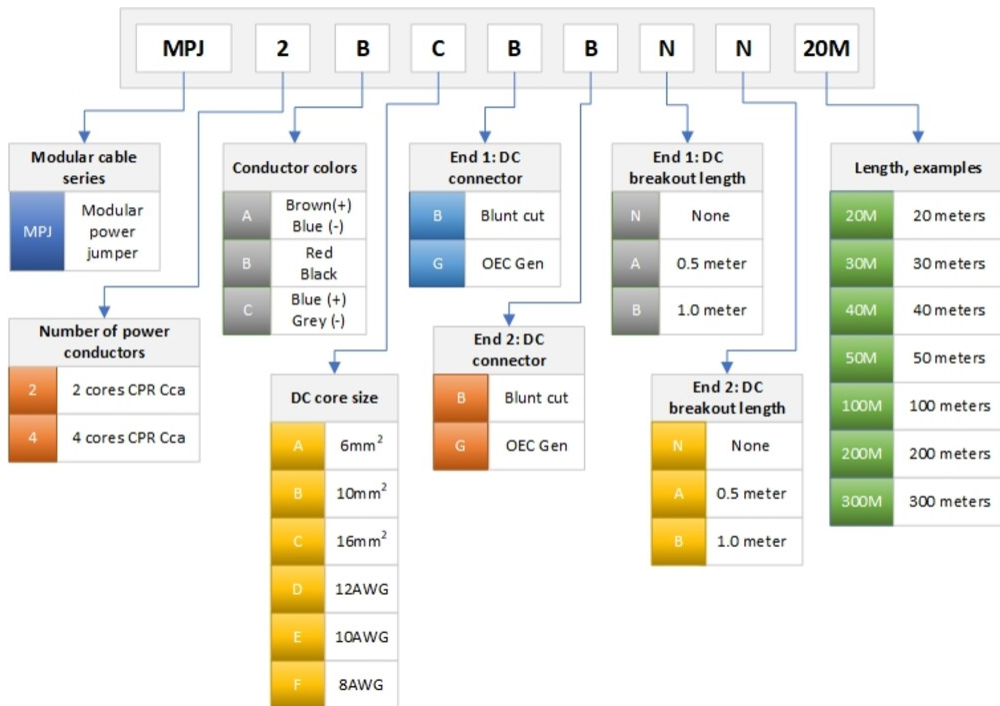

Material Specifications

Dielectric Material	PVC
Filler Material	Polypropylene
Jacket Material	PE

Mechanical Specifications

Minimum Bend Radius	156 mm 6.142 in
Cable Retention Strength, maximum	90 N (OEC GEN)

Environmental Specifications

Operating Temperature	-40 °C to +75 °C (-40 °F to +167 °F)
Environmental Space	UV resistant for outdoor and/or direct burial installations
Flame Test Method	CMP
Flammability Rating	CMP