

SEC3-A5A1D2BA000



NOVUX™ SEC Closure, splice only, no adapters, 1x factory-installed 1:2 bare splitter, mounting included, black

- Design optimized for FTTH façade applications with gray and black colors
- Agnostic to connectivity technologies: splice, connector, field-installable connector for agility and flexibility
- Innovative removable hinge design allows cover to open from the left, right, or top
- Identification plate for either QR code or customer logo
- QR code and CommScope cTrak® app for one-click access to all product information

Product Classification

Regional Availability	EMEA
Regional Availability Note	Contact your local CommScope representative for specific availability
Product Type	In-line, rectangular fiber closure
Product Brand	NOVUX™
Product Series	SEC100


General Specifications

Cable Capacity, Branch	2 Round 1.8–7.0 mm (0.07–0.27 in)
Cable Capacity, Drop	6 Round 1.8–7.0 mm (0.07–0.27 in)
Cable Capacity, Feeder	2 Round 9.0–12.0 mm (0.35–0.47 in)
Cable Ports Quantity, total	10 round ports
Cable Sealing Type	Gasket/grommet configuration
Closure Sealing Type	Hinged with lock
Closure Style	In-line
Color	Gray
Mounting	Facade Wall
Network Area Type	Drop
Port Type	No adapter No adapter
Splice Tray Included, quantity	3
Splice Tray Type Included	12-way, heat shrink
Splices per Tray, quantity	12
Splicing Capacity, maximum	32

SEC3-A5A1D2BA000

Splicing Capacity, Single Fusion, maximum	32
Splicing Type, Supported	Single fusion
Splitter Type	1 x 2
Splitter, quantity	1
Dimensions	
Height	117 mm 4.606 in
Width	210 mm 8.268 in
Depth	75 mm 2.953 in

Ordering Tree

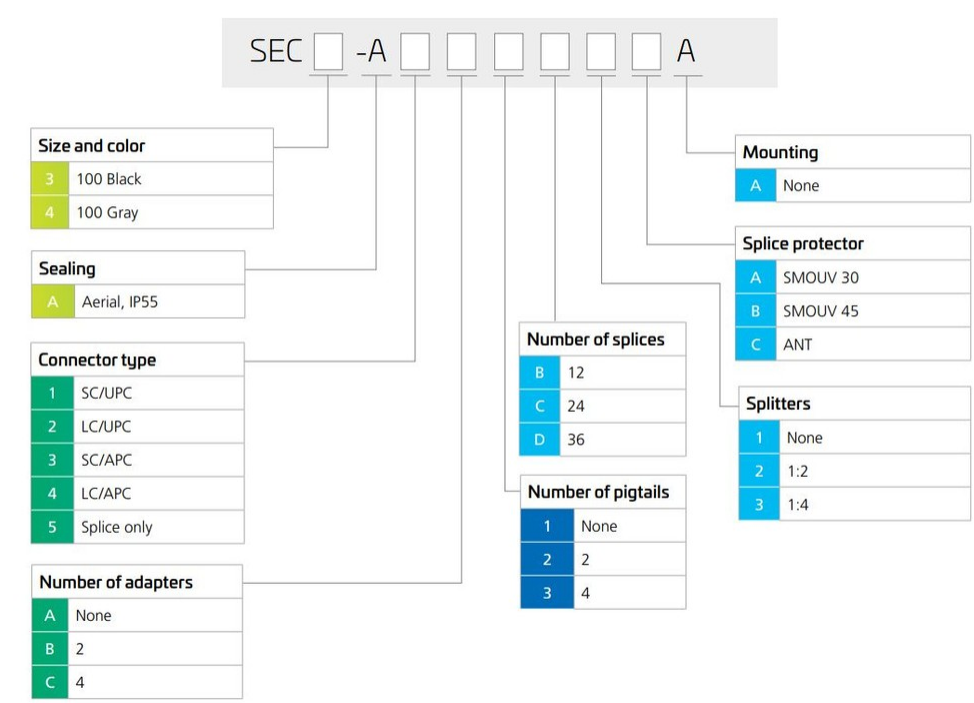

Optical Specifications

Fiber Type	G.657.A1 G.657.A2 G.657.B3
------------	--------------------------------

Environmental Specifications

Environmental Space	Facade Outdoor
Qualification Standards	IP55
UV Resistance	UV stabilized

SEC3-A5A1D2BA000

Packaging and Weights

Included	1x factory-installed 1:2 bare splitter
Packaging quantity	1
Packaging Type	Box Carton

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system