


1RU-SP3232001 | 1RU SPLTR PNL 2X32 APC/SC

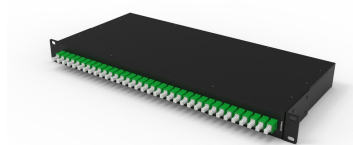

1RU panel, 2X32 split ratio, 1 splitter, SC/APC connectors

Product Classification

Regional Availability	Asia Australia/New Zealand China EMEA India Latin America North America
Product Type	Splitter module
Product Series	1RU

General Specifications

Functionality	Splitting
Technology Type	Planar lightwave circuit (PLC)
Distribution Type	2 x 32 splitter
Interface, Input	SC
Interface Feature, Input	APC
Interface, Output	SC
Interface Feature, Output	APC
Splitter, quantity	1

Dimensions

Height	43.69 mm 1.72 in
Width	482.6 mm 19 in
Length	199.89 mm 7.87 in

Optical Specifications

Directivity, minimum	55 dB
Polarization Dependent Loss, maximum	0.4 dB
Uniformity, maximum	2.65 dB
Wavelength Range	1260–1650 nm
Insertion Loss, Splitter, maximum	18.2 dB
Return Loss, Splitter, minimum	50 dB

1RU-SP3232001 | 1RU SPLTR PNL 2X32 APC/SC

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Relative Humidity	5%–95%, non-condensing

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

