


41108A-3

Stand-off Adapter with clamp, 2.5 in, for 5–6 in round members

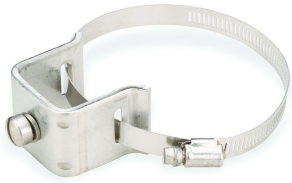

OBSOLETE

Replaced By:

TTS3-56

Three-way Stand-off Adapter for 5–6 in round members

Product Classification

| | |
|----------------------|---------------------------------|
| Product Type | Adapter |
| Ordering Note | CommScope® non-standard product |

General Specifications

| | |
|---------------------|--------------------|
| Adapter Type | Stand-off adapter |
| Mounting | 3/8 in tapped hole |

Dimensions

| | |
|---------------------------|---------------------|
| Inside Width | 44.45 mm 1.75 in |
| Outside Width | 50.8 mm 2 in |
| Inside Length | 60.452 mm 2.38 in |
| Outside Length | 87.376 mm 3.44 in |
| Material Thickness | 2.667 mm 0.105 in |

Material Specifications

| | |
|----------------------|-----------------|
| Material Type | Stainless steel |
|----------------------|-----------------|

Mechanical Specifications

| | |
|-------------------------------------|-----------------------|
| Installation Torque, maximum | 13 ft lb 17.626 N-m |
| Installation Torque, minimum | 11 ft lb 14.914 N-m |

41108A-3

Maximum Loading Double stack, 1-5/8 in cable

Packaging and Weights

Height, packed 24 cm | 9.449 in

Width, packed 14 cm | 5.512 in

Length, packed 14 cm | 5.512 in

Included Clamp

Packaging quantity 10

Weight, gross 3.3 kg | 7.275 lb

Regulatory Compliance/Certifications

Agency

REACH-SVHC

ROHS

Classification

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant