


# UJG2PMERP

## Base Product

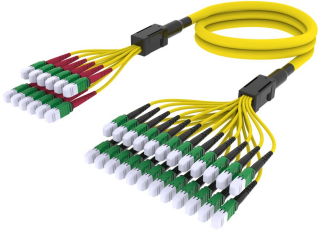

Ultra Low Loss (ULL) Singlemode MPO24 (Unpinned) to MPO12 (Unpinned) Pre-terminated Trunk Cable, 288-Fiber, 12-fiber Rollable Ribbon Central Tube, Low Smoke Zero Halogen (LSZH)/Riser

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Color, boot A</b>	Red
<b>Color, connector A</b>	Green
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Green
<b>Construction Type</b>	Rollable ribbon
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-24/APC Female
<b>Interface, Connector B</b>	MPO-12/APC Female
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	288

## Dimensions


<b>Breakout Length, connector A</b>	1,244.6 mm   49 in
<b>Breakout Length, connector B</b>	787.4 mm   31 in
<b>Cable Assembly Length Range (m)</b>	3 – 999

# UJG2PMERP

**Cable Assembly Length Range (ft)**

10 – 999

## Ordering Tree

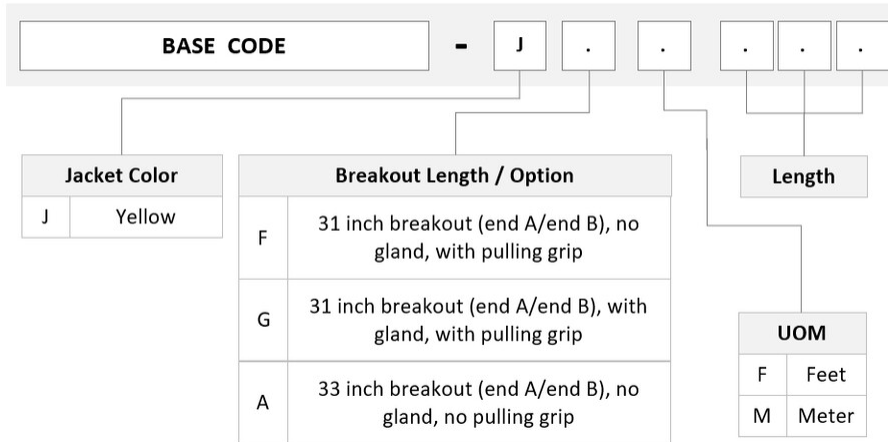

## Mechanical Specifications

**Cable Retention Strength, maximum**

11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode**

Singlemode

**Fiber Type**

G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature**

-10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space**

Dual Rated LSZH/Riser

## Regulatory Compliance/Certifications

**Agency**

**Classification**

ANATEL

Compliant

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant

# UJG2PMERP

---



## Included Products

- 760239308  
N-288-CN-RR-F12YL/8G1/99G  
/C - Fiber indoor cable, All-Dielectric, LSZH/Riser-Rated, Gel-Free, Central Tube Rollable Ribbon, 288 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Cca flame rating
- 860638318 - MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm
- 860651708 - TeraSPEED® MPO Female 24 Fiber Connector, green, 3.6 mm