


UJG2XMER3

Base Product

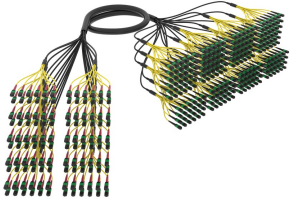

Ultra Low Loss (ULL) Singlemode MPO24 (pinned) to MPO12 (Unpinned) Pre-terminated Trunk Cable, 2880-Fiber, 12-fiber Rollable Ribbon Central Tube, Indoor/Outdoor, Low Smoke Zero Halogen (LSZH)/Riser

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Red
Color, connector A	Green
Color, boot B	Black
Color, connector B	Green
Construction Type	Rollable ribbon
Furcation Color	Yellow
Interface, Connector A	MPO-24/APC Male
Interface, Connector B	MPO-12/UPC Female
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	
Total Fibers, quantity	2880

Dimensions

Cable Assembly Length Range (m)	5 – 999
Cable Assembly Length Range (ft)	15 – 999
Cable Assembly Length Range (km)	1.00 – 2.00

UJG2XMER3

Ordering Tree

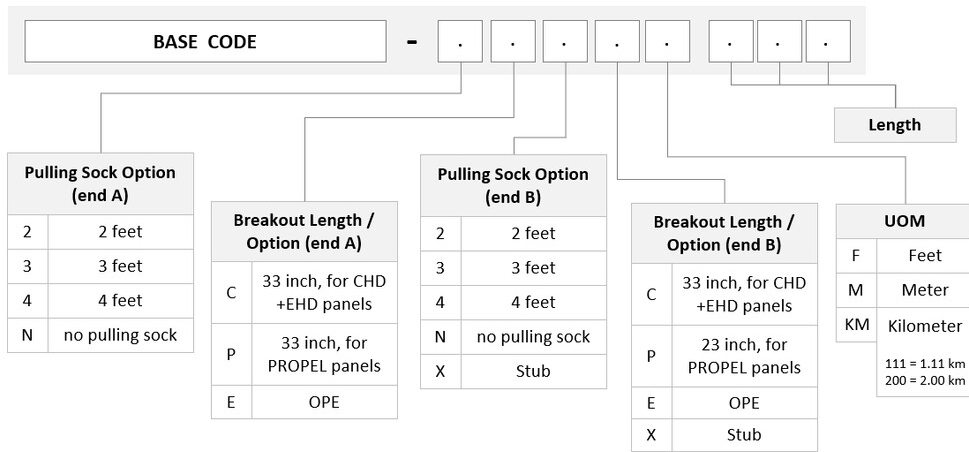

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor/Outdoor

Packaging and Weights

Packaging Type Wood reel

Regulatory Compliance/Certifications

Agency **Classification**

ANATEL Compliant



Included Products

UJG2XMER3

- 760253186
Z-2880-CN-RR-F12BK/8G1/99L
/C – Fiber indoor/outdoor cable, All-Dielectric, LSZH, Gel-Free, Riser Rated, Central Core Rollable Ribbon, 2880 fiber, Singlemode G.657.A2, Feet jacket marking, Black jacket color, Cca flame rating
- 860638318 – MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm
- 860651709 – TeraSPEED® MPO Male 24 Fiber Connector, green, 3.6 mm