

## OFDC-C12 / OFDC-B8G WALL AND POLE MOUNTING OPTIONS

### Contents

1	General product information .....	1
2	Wall mounting OFDC-C12 & OFDC-B8G.....	1
3	Pole mounting OFDC-C12 & OFDC-B8G.....	2
4	Pole mounting kit with 2 metal brackets for OFDC-C12 .....	3
5	Pole mounting with metal bracket and straps for OFDC-B8G .....	3
6	Pole mounting with metal bracket and two (2) screws for OFDC-B8G.....	4
7	Trademarks and patents .....	4
8	Contact information.....	4

### 1 General product information

This document is an addendum to OFDC-B8G and OFDC-C12.

### 2 Wall mounting OFDC-C12 & OFDC-B8G




2.1 Mark the four (4) positions for the screws in the wall (mounting tabs).



- 2.2 Drill the four (4) holes and install the screws (screws are not included in kit).
- 2.3 Recommended screw type: DIN 571-6 x 60 -A2.
- 2.4 For concrete wall, use drill bit diameter: 10 mm/0.39 inch.
- 2.5 Install the closure over the screws and tighten.

### 3 Pole mounting OFDC-C12 & OFDC-B8G

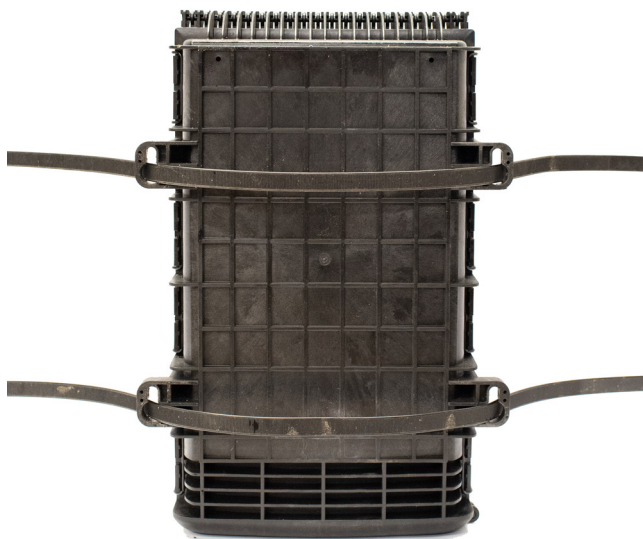

- 3.1 Direct Pole mounting for OFDC-B8G with plastic or metal straps (tie wraps).
- 3.2 Guide the straps through the mounting tabs and fix securely to the pole.

## 4 Pole mounting kit with 2 metal brackets for OFDC-C12



- 4.1 Guide the straps through the holes in the metal brackets as shown.
- 4.2 Straps are not included in the kit (OFDC-C12-POLE-BRACKET-KIT).




- 4.3 Fix the two (2) brackets to the pole horizontally.
- 4.4 Distance between the two (2) brackets is from the screw positions (165 mm / 6.5 inches).
- 4.5 Install the OFDC-C12 terminal over the screws and tighten the nuts.

## 5 Pole mounting with metal bracket and straps for OFDC-B8G



- 5.1 Straps are not included in the kit (OFDC-B8G-POLE MNT BRKT KIT).
- 5.2 Fix the metal bracket with two(2) straps to the pole as shown.
- 5.3 Install the OFDC-B8G terminal over the screws and tighten the nuts.

## 6 Pole mounting with metal bracket and two (2) screws for OFDC-B8G

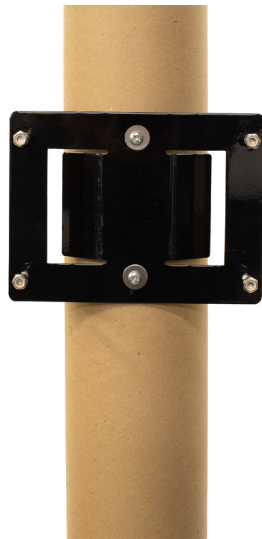

- 6.1 When allowed, the metal bracket can be fixed to the pole with 2 screws.
- 6.2 Install the OFDC-B8G terminal over the four (4) screws and tighten the nuts (see 5.3)

**For strand mount installation please refer to the following Commscope documents:**

OFDC-B8G  
OFDC-C12

## 7 Trademarks and patents

All trademarks identified by ® or ™ are registered trademarks or trademarks, respectively, of CommScope, Inc. This document is for planning purposes only and is not intended to modify or supplement any specifications or warranties relating to CommScope products or services. CommScope is committed to the highest standards of business integrity and environmental sustainability, with a number of CommScope's facilities across the globe certified in accordance with international standards, including ISO 9001, TL 9000, and ISO 14001.

Further information regarding CommScope's commitment can be found at [www.commscope.com/About-Us/Corporate-Responsibility-and-Sustainability](http://www.commscope.com/About-Us/Corporate-Responsibility-and-Sustainability).

This product may be covered by one or more U.S. patents or their foreign equivalents. For patents, see [www.cs-pat.com](http://www.cs-pat.com).

## 8 Contact information

Visit our website or contact your local CommScope representative for more information.

For technical assistance, customer service, or to report any missing/damaged parts, visit us at: <http://www.commscope.com/SupportCenter>