


# MCG23HDX-10MB

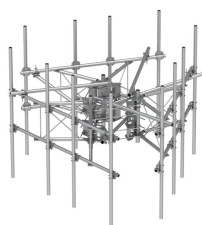

G23HDX High Capacity 3-Sector Monopole Base Frame with 10.5 ft x 2.88 in OD face pipes. Antenna Pipes/pipe mounts not included.

## Product Classification

Product Type	High capacity monopole sector frame
Product Series	G2
Ordering Note	NSTD445 Compliant

## General Specifications

Mounting	Monopole, 381–1270 mm (15–50 in) OD
Pipe, quantity	0
Sectors, quantity	3

## Dimensions

Face Width	3.2 m   10.5 ft
Width	3,200.4 mm   126 in
Face Support Pipe Diameter	73.025 mm   2.875 in
Mounting Diameter, maximum	1270 mm   50 in
Mounting Diameter, minimum	381 mm   15 in
Pipe Outer Diameter	73.025 mm   2.875 in
Stand-off Distance	1,066.8 mm   42 in

## Material Specifications

Material Type	Hot dip galvanized steel
---------------	--------------------------

## Mechanical Specifications

Wind Rating	For Specifications, please contact your local ANDREW representative
Wind Rating Test Method	TIA/EIA-222

## Packaging and Weights

Included	Mounting hardware   Ring mounts (2)   Sector frames (3)   Stiff arm
----------	---

# MCG23HDX-10MB

---

Packaging quantity	1
Weight, net	776.097 kg   1711 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## \* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
-------------	--