


# MCG23HDX-12M1296

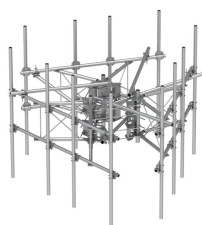

G23HDX High Capacity 3-Sector Monopole Sector Frame, 12.5 ft x 2.88 in OD face pipes, includes twelve 2.88 OD x 96 in pipes

## Product Classification

Product Type	High capacity monopole sector frame
Product Series	G2
Ordering Note	NSTD445 Compliant

## General Specifications

Mounting	Monopole, 381–1270 mm (15–50 in) OD
Pipe, quantity	12
Sectors, quantity	3

## Dimensions

Height	2,438.4 mm   96 in
Face Width	3.81 m   12.5 ft
Width	3,810 mm   150 in
Pipe Length	2,438.4 mm   96 in
Face Support Pipe Diameter	73.025 mm   2.875 in
Mounting Diameter, maximum	1270 mm   50 in
Mounting Diameter, minimum	381 mm   15 in
Pipe Outer Diameter	73.025 mm   2.875 in
Stand-off Distance	1,066.8 mm   42 in

## Material Specifications

Material Type	Hot dip galvanized steel
---------------	--------------------------

## Mechanical Specifications

Wind Rating	For Specifications, please contact your local ANDREW representative
Wind Rating Test Method	TIA/EIA-222

# MCG23HDX-12M1296

## Packaging and Weights

Included	Mounting hardware   Pipe mounts   Plain end pipes (12)   Ring mounts (2)   Sector frames (3)   Stiff arm
Packaging quantity	1
Weight, net	1,159.382 kg   2556 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## \* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
-------------	--