


U3VQVQZTL

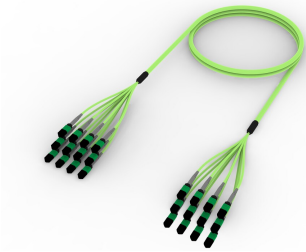

Ultra Low Loss (ULL) OM5 MPO8 APC (Non-Pinned) to MPO8 APC (Pinned), Fiber Trunk Cable Assembly, 96-Fiber, LSZH B2ca

Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Gray
Color, boot B	Gray
Color, connector A	Green
Color, connector B	Green
Connector A, quantity	12
Connector B, quantity	12
Construction Type	Stranded
Fibers per Subunit, quantity	8
Furcation Color	Lime green
Interface, Connector A	MPO-08/APC Female
Interface, Connector B	MPO-08/APC Male
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	96

Dimensions


Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305

U3VQVQZTL

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

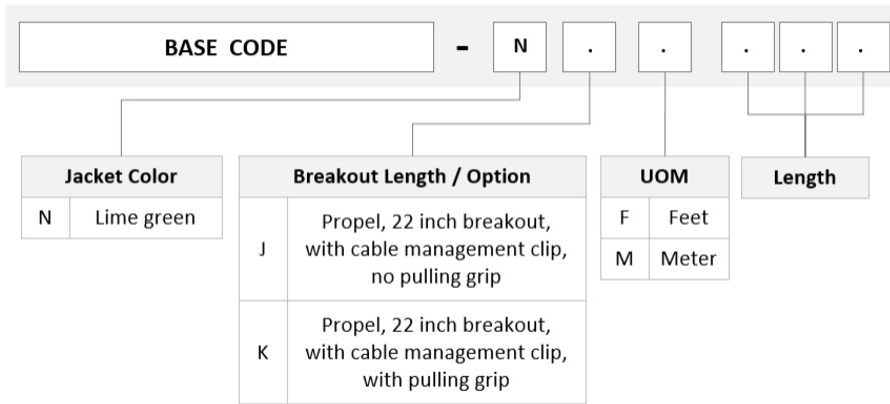

Mechanical Specifications

Cable Retention Strength, maximum

11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode

Multimode

Fiber Type

OM5, LazrSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance

B2ca

Environmental Space

Indoor | Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant



U3VQVQZTL

Included Products

- 760253113 N-096-MP-5G-F08LM/20T/B2 - LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable with 2.0mm Subunits, 96 fiber
- 860662230 - MPO8,ULL,MM,MALE,APC,GREEN,2MM
- 860662232 - MPO8,ULL,MM,FEMALE,APC,GREEN,2MM