


# U3VRZRZ8N

Base Product

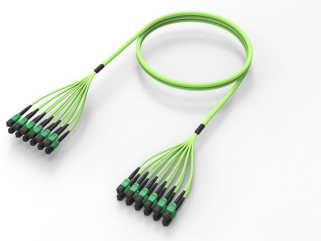

Ultra Low Loss (ULL) OM5 MPO16 APC (Pinned) to MPO16 APC (Pinned), Fiber Trunk Cable Assembly, 192-Fiber, LSZH B2ca

## Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel   SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

Connector A, quantity	12
Color, boot A	Black
Color, connector A	Green
Connector B, quantity	12
Color, boot B	Black
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-16/APC Male
Interface, Connector B	MPO-16/APC Male
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	16
Total Fibers, quantity	192


## Dimensions

Breakout Length	22 in
-----------------	-------

# U3VRZRZ8N

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

## Ordering Tree

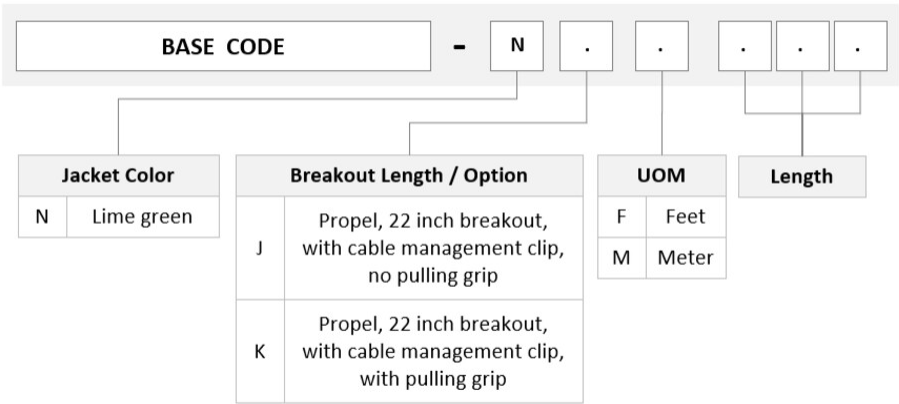

## Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 °   4.40 lb @ 90 °
-----------------------------------	---------------------------------

## Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM5, LazrSPEED®

## Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	B2ca
Environmental Space	Indoor   Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# U3VRZRZ8N

---



## Included Products

- |                                       |   |                                                                                                                                                                                                                |
|---------------------------------------|---|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| 760251071<br>N-192-MP-5G-F16LM/30T/B2 | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable, 192 fiber with 16-fiber, 3.0mm subunits, Gel-free, Multimode OM5, Feet jacket marking, Lime green jacket color, B2ca flame rating |
| 860659158                             | - | Fiber Optic Connector Kit, multimode, OM3/OM4, MPO-16/APC, ULL, pinned, green, for 3 mm cable                                                                                                                  |