


U3XQPQXTU

Base Product

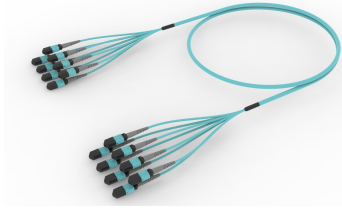

Ultra Low Loss (ULL) OM4 MPO8 (Non-Pinned) to MPO8 (Pinned), Fiber Trunk Cable Assembly, 64-Fiber, LZSH B2ca

Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	8
Color, boot A	Gray
Color, connector A	Aqua
Connector B, quantity	8
Color, boot B	Gray
Color, connector B	Aqua
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/UPC Female
Interface, Connector B	MPO-08/UPC Male
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	64

Dimensions

Breakout Length	22 in
------------------------	-------

U3XQPQXTU

Included Products

- 760253121
N-064-MP-5K-F08AQ/20T/B2 - Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk with 2.0mm Subunits, 64 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame rating
- 860659018 - MPO-08, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 2mm
- 860659024 - MPO-08, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 2mm