


# UGGQXQXTN

## Base Product

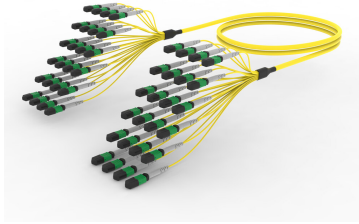

Ultra Low Loss (ULL) Singlemode MPO8 (Pinned) to MPO8 (Pinned), Fiber Trunk Cable Assembly, 192-Fiber, Plenum

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Product Brand

Propel | SYSTIMAX ULL

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

|                                     |                         |
|-------------------------------------|-------------------------|
| <b>Connector A, quantity</b>        | 24                      |
| <b>Color, boot A</b>                | Gray                    |
| <b>Color, connector A</b>           | Green                   |
| <b>Connector B, quantity</b>        | 24                      |
| <b>Color, boot B</b>                | Gray                    |
| <b>Color, connector B</b>           | Green                   |
| <b>Construction Type</b>            | Stranded                |
| <b>Furcation Color</b>              | Yellow                  |
| <b>Interface, Connector A</b>       | MPO-08/APC Male         |
| <b>Interface, Connector B</b>       | MPO-08/APC Male         |
| <b>Jacket Color</b>                 | Yellow                  |
| <b>Polarity</b>                     | Method B Enhanced (ULL) |
| <b>Fibers per Subunit, quantity</b> | 8                       |
| <b>Total Fibers, quantity</b>       | 192                     |

## Dimensions

|                        |       |
|------------------------|-------|
| <b>Breakout Length</b> | 22 in |
|------------------------|-------|

# UGGQXQXTN

**Cable Assembly Length Range (m)** 3 – 305  
**Cable Assembly Length Range (ft)** 10 – 999

## Ordering Tree



## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Singlemode  
**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)  
**Environmental Space** Indoor | Plenum

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| ANATEL        | Compliant  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |



# UGGQXQXTN

---

## Included Products

- 760248110  
P-192-MP-8G1-F08YL/20T - Fiber indoor cable, Plenum MPO Trunk, 192 fiber multi-unit with 8 fiber subunits, Singlemode G. 657.A2/B2, Feet jacket marking, Yellow jacket color
- 860659022 - MPO-08, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm