


Base Product

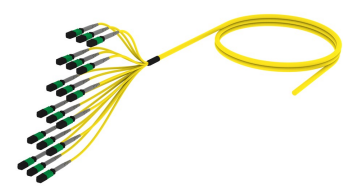

Ultra Low Loss (ULL) Singlemode MPO8 (Pinned) to unconnectorized, Fiber Trunk Cable Assembly, 144-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	18
Color, boot A	Gray
Color, connector A	Green
Connector B, quantity	0
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-08/APC Male
Interface, Connector B	Unterminated
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	144

Dimensions


Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305

UGGQXUCTM

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

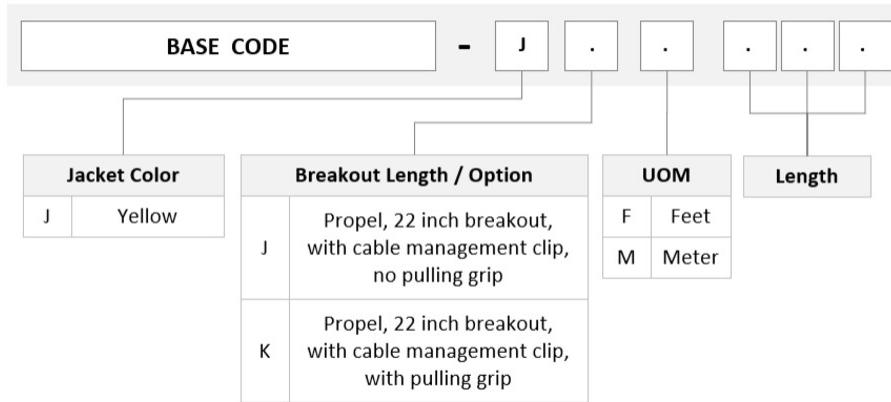

Mechanical Specifications

Cable Retention Strength, maximum

11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode

Singlemode

Fiber Type

G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space

Indoor | Plenum

Regulatory Compliance/Certifications

Agency

Classification

ANATEL

Compliant

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system



Included Products

760248109

- Fiber indoor cable, Plenum MPO Trunk, 144 fiber multi-unit with 8 fiber subunits, Singlemode G.

UGGQXUCTM

P-144-MP-8G1-F08YL/20T	657.A2/B2, Feet jacket marking, Yellow jacket color
860659022	– MPO-08, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 2mm