


# UJVQZUCTM

## Base Product

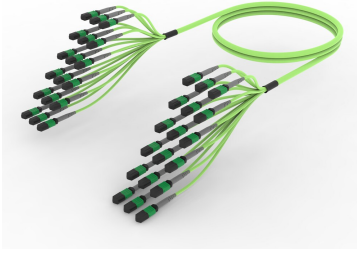

Ultra Low Loss (ULL) OM5 MPO APC (Pinned) to Unconnectorized, Fiber Trunk Cable Assembly, 144-Fiber, Dual Rated (OFNR/LSZH)

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber trunk cable assembly   |
| <b>Product Brand</b>         | Propel   SYSTIMAX ULL  |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                                     |                         |
|-------------------------------------|-------------------------|
| <b>Connector A, quantity</b>        | 18                      |
| <b>Color, boot A</b>                | Gray                    |
| <b>Color, connector A</b>           | Green                   |
| <b>Connector B, quantity</b>        | 0                       |
| <b>Construction Type</b>            | Stranded                |
| <b>Furcation Color</b>              | Lime green              |
| <b>Interface, Connector A</b>       | MPO-08/APC Male         |
| <b>Interface, Connector B</b>       | Unterminated            |
| <b>Jacket Color</b>                 | Lime green              |
| <b>Polarity</b>                     | Method B Enhanced (ULL) |
| <b>Fibers per Subunit, quantity</b> | 8                       |
| <b>Total Fibers, quantity</b>       | 144                     |

## Dimensions

|  |         |
|--|---------|
| <b>Breakout Length</b>                 | 22 in   |
| <b>Cable Assembly Length Range (m)</b> | 3 – 305 |

# UJVQZUCTM

Cable Assembly Length Range (ft) 10 – 999

## Ordering Tree



## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM5, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |

## Included Products

- 760253114 N-144-MP-5G-F08LM/20T/B2 – Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 144 fiber with 2.0 mm Subunits, Multimode OM5, Gel-free, Meters jacket marking, Lime green jacket color, B2ca Flame rating
- 860662230 – MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm