UJVRZRZ8H

Base Product

Ultra Low Loss (ULL) OM5 MPO16 (Pinned) to MPO16 (Pinned), Fiber Trunk Cable Assembly, 48-Fiber, Dual Rated (OFNR/LSZH)

Product Classification

Regional Availability	Asia	Australia/New Zealand	China	Europe	India	Latin America	Middle East/Africa	North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative	For lengths greater than 999 ft (304 m), orders must be in meters	Minimum length may vary based on cable configuration

General Specifications

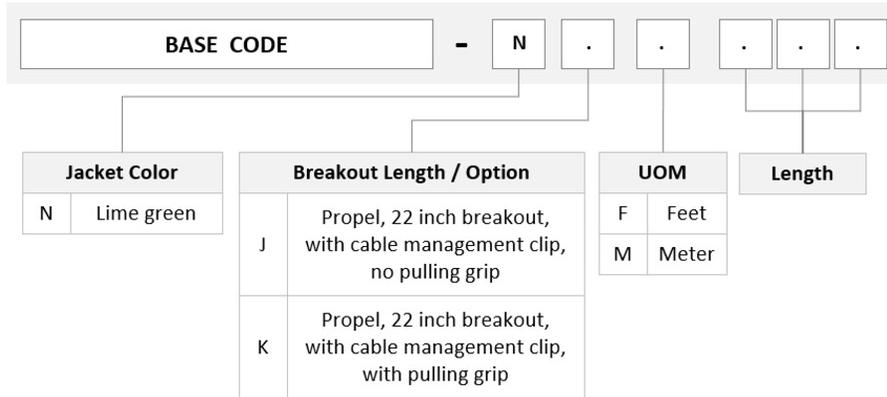|	
Connector A, quantity	3
Color, boot A	Black
Color, connector A	Green
Connector B, quantity	3
Color, boot B	Black
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-16/APC Male
Interface, Connector B	MPO-16/APC Male
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	16
Total Fibers, quantity	48

Dimensions

Breakout Length	22 in

COMMSCOPE®

UJVRZRZ8H

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

BASE CODE	– N	.	.	.	.	.

Jacket Color		Breakout Length / Option		UOM		Length
N	Lime green	J	Propel, 22 inch breakout, with cable management clip, no pulling grip	F	Feet	
		K	Propel, 22 inch breakout, with cable management clip, with pulling grip	M	Meter	

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM5, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

COMMSCOPE®

Included Products

760251066 N-048-MP-5G-F16LM/30T/B2	–	Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable, 48 fiber with 16-fiber, 3.0mm subunits, Gel-free, Multimode OM5, Feet jacket marking, Lime green jacket color, B2ca flame rating
860659158	–	Fiber Optic Connector Kit, multimode, OM3/OM4, MPO-16/APC, ULL, pinned, green, for 3 mm cable

COMMSCOPE®